


TH-440 Scissors Style

Acompact, high-quality tool designed to perform the six most common electrical wiring functions.

- Made of 1.125" (28,57 mm) heat-treated carbon steel
- Handles a variety of terminal and connector styles, insulated and non-insulated
- Range of 22–10 AWG
- 3M Terminals and Connectors are UL Listed and CSACertified when used with the TH-440

Features:

1. Anvil-type wire cutter for clean cuts.
2. Crimp dies for 22–10 AWG insulated terminals, connectors and closed-end connectors.
3. Cut-off dies for mild steel and non-ferrous screws.
4. Crimp dies for 22–10 AWG non-insulated terminals and connectors.
5. Wire stripping stations for circumferencial cut-less effort.
6. Crimp die for 7 and 8 mm ignition parts.
7. Cushioned, vinyl grips, red.

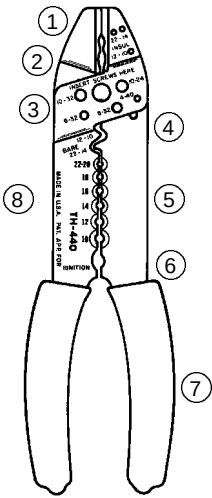

For specific tooling applications, refer to the smallest unit container or the Tool Selection Guides in the Appendix.

| Product<br>(add package code<br>when ordering) | UPC<br>(054007-) | Wire<br>Range | Tools/<br>Carton | Tools/<br>Case |
|------------------------------------------------|------------------|---------------|------------------|----------------|
| TH-440                                         | 60825            | 22-10         | 1                | 10             |