


DOC NO	ISSUE	REVISION	PRODUCT REF.	DATE	QUALITY PLAN
QF/RD/05	01	00	FAR0804	17.10.14	
TECHNICAL SPECIFICATIONS				SIGNATURE	
				PRESIDENT (TECHNICAL)	

TEMPORARY HORIZONTAL ANCHORAGE LINE [(HORIZON (FAR0804))]

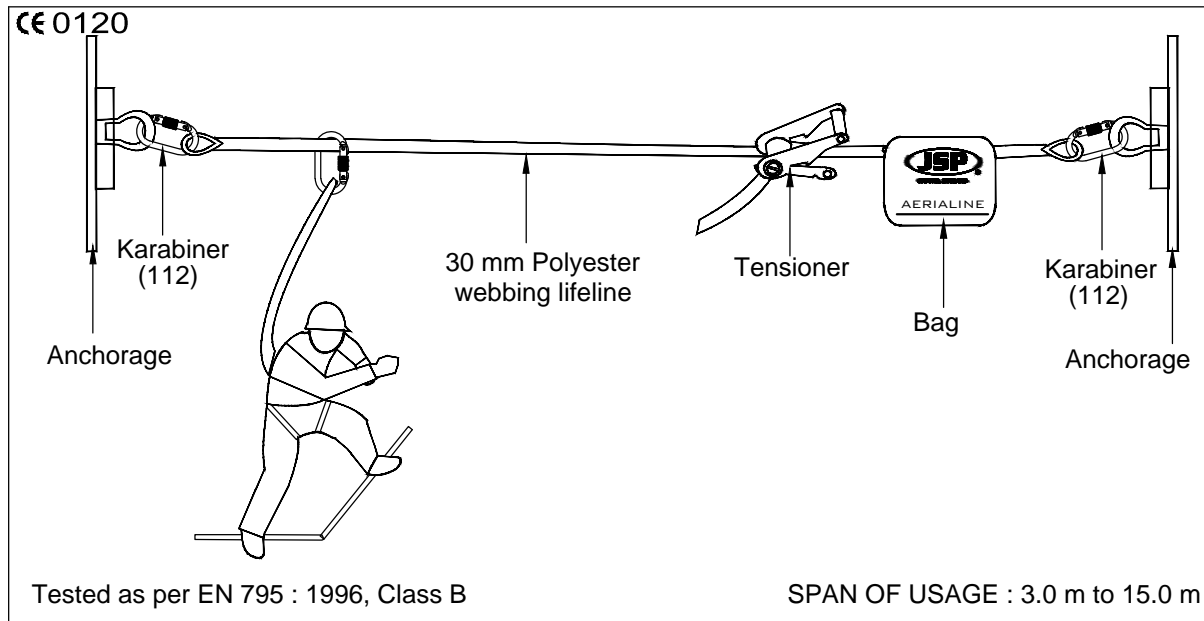

DESIGN

- Consists of 30 mm polyester webbing lifeline.
- Equipped with ratchet tensioner to tighten the line.
- Two auto locking karabiner (112) provided for attachment to anchor points.
- Suitable for use by two personnel simultaneously.

WEBBING

- Material : Polyester.
- Width : 30±1mm.
- Breaking strength : 25 kN (Min).

KARABINERS

- Two auto locking karabiner (112), tested as per EN 362:2004
- Material : Alloy Steel.
- Plating : Galvanized with Golden Yellow/Silver Passivation.
- Finish : Shot Blasted.

RATCHET TENSIONER

- Made up of Alloy steel.
- Capable of tensioning the line by rotary motion.
- Spring loaded locking & unlocking mechanism.

VITAL TEST COMPLIANCE

- Static Strength : 10 kN for 3 Minutes.
- Dynamic Performance : 2 mtr. free fall with mass of 100kg.

WEIGHT

- 3450 gm ±10 gm.

