




Product Datasheet

ENGLISH

Equipment wire 3/24/0.07mm



Cross Section:

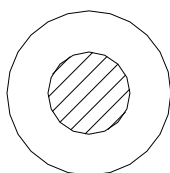

Characteristics:

Relevant Standards:

Operating Voltage: 250 V

Operating Temperature (°C): -40 to 105 °C

Applications: Extra-flexible wires, designed for connecting mobile assemblies

Construction:

Inner Conductor: Bare copper

Insulation: PVC

Marking: No

Specification:

Conductor				Overall Diameter (mm)		Conductor resistance (Ω/Km, at 20°C)	Long term current Rating (A)
Size AWG	Area (mm ²)	O/D (mm)	Stranding (mm)	Min.	Max.	Max.	Max.
23	0.30	0.68	3/24/ 0.07	1.50	1.70	69.2	5.0

Product Range:

RS Code
8738863
8738867

Description
Red equipment wire 3/24/0.07mm 100m
Green equipment wire 3/24/0.07mm 100m

RoHS✓