



# DNG

RAL 7030 grey

Standard length :  
2000 mm  
Material :  
uPVC rigid


uPVC slotted panel trunking

**TEHALIT**

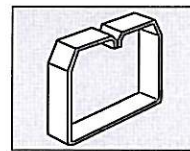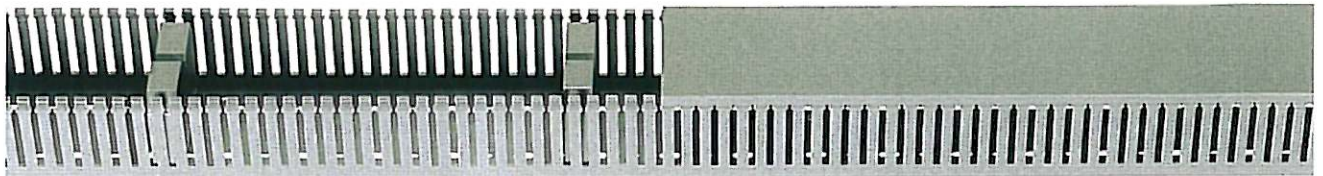


Cable retaining clip:  
50 pieces


Part no.	External Height/width mm	Capacity mm <sup>2</sup>	Box qty. m	Slot type		Part no.	
				A	B		
DNG 20020	19/19	226	64		•	-	-
DNG 25025	24/25	529	48	•		-	-
DNG 25037	24/37	684	64	•		-	-
DNG 37020	36/19	498	32		•	-	-
DNG 37037	36/37	1026	32	•		-	-
DNG 50020	49/19	765	20		•	-	-
DNG 50025	49/24	839	18	•		-	-
DNG 50037	49/37	1435	40	•		-	-
DNG 50050	49/49	1886	48	•		DN 50050/3	-
DNG 50075	49/74	3145	20	•		DN 50075/3	-
DNG 50100	49/99	4225	24	•		DN 50100/3	-
DNG 50125	49/124	5305	18	•		DN 50125/3	-
DNG 75025	73/24	1331	32	•		-	-
DNG 75037	73/37	2300	40	•		-	-
DNG 75050	73/49	3055	20	•		DN 75050/3	-
DNG 75075	73/74	4780	16	•		DN 75075/3	-
DNG 75100	73/99	6505	16	•		DN 75100/3	-
DNG 75125	73/124	8161	12	•		DN 75125/3	-
DNG 100050	98/49	4135	24	•		DN 100050/3	-
DNG 100075	98/74	6460	16	•		DN 100075/3	-
DNG 100100	98/99	8692	12	•		DN 100100/3	-

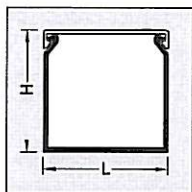


Height/width

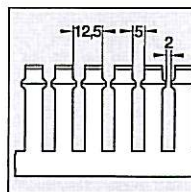


Slotted side A

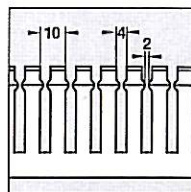

Slotted side B

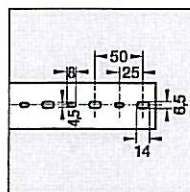

Base punching to Din 43659 for 20, 25, 37 and 50 mm trunking.

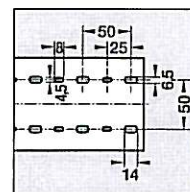

Base punching to DIN 43659 for 75, 100 and 125 mm trunking.