


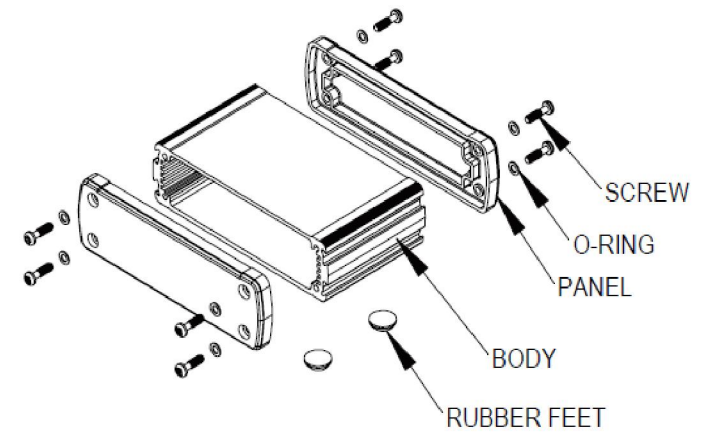


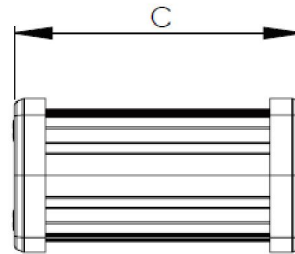

RS Stock No.13689180001
RS Stock No.13689200001
RS Stock No.13689210001
RS Stock No.13689220001
RS Stock No.13689230001
RS Stock No.13689240001

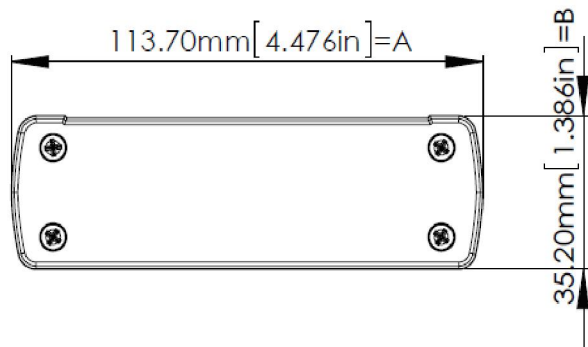

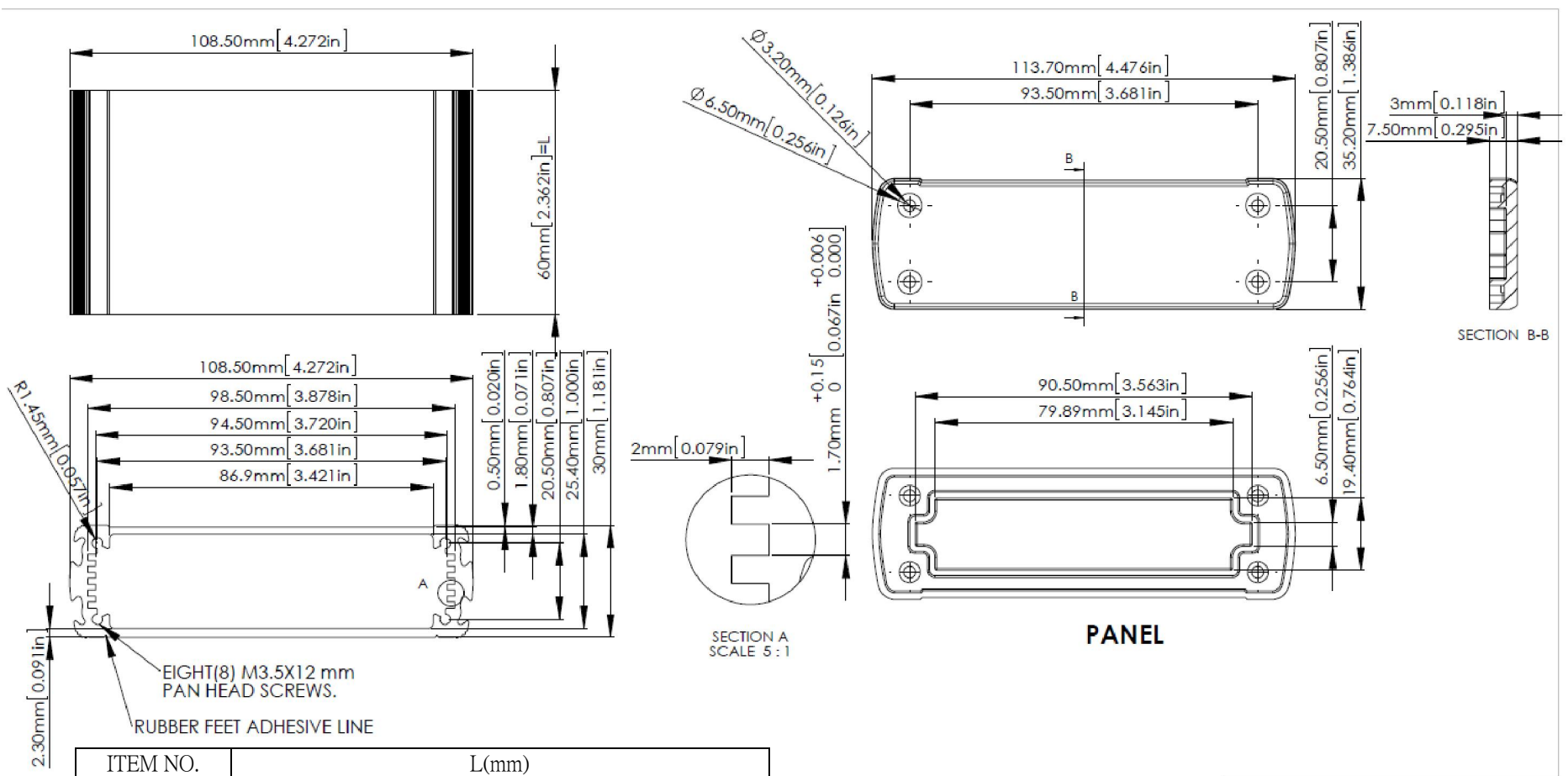

ITEM NO.	L(mm)
13689180001	60mm
13689200001	110mm
13689210001	160mm
13689220001	60mm
13689230001	110mm
13689240001	160mm

According to ISO 2768-m	
Measuring DIM=L	Tolerances
0.5<L<=3.0mm	±0.1mm
3.0<L<=6.0 mm	±0.1mm
6.0<L<=30.0 mm	±0.2mm
30.0<L<=120.0 mm	±0.3mm
120.0<L<=400.0 mm	±0.5mm
400.0<L<=1000.0 mm	±0.8mm