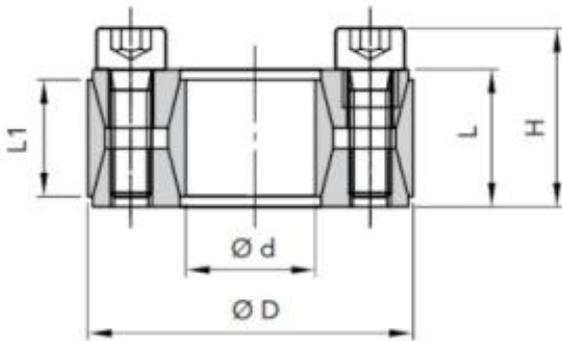


06400030

RCK 40 - Not self centering

2D Technical Drawing

Dynamic 3D View
Technical Specifications

| | |
|--|----------|
| Part number (CODE) | 06400030 |
| $\varnothing d$ (DD) mm | 30 |
| $\varnothing D$ (D) mm | 55 |
| L1 (L1) mm | 17 |
| L (L) mm | 20 |
| H (H) mm | 28 |
| Maximum torque Mt (MT) Nm | 530 |
| Clamping pressure - Shaft (CPS) N/mm ² | 176 |
| Clamping pressure - Hub (CPH) N/mm ² | 96 |
| Clamping screws DIN 912 MAT. 12.9 - N. (CSN) | 10 |
| Clamping screws DIN 912 MAT. 12.9 - Type (CSTY) | M6x18 |
| Clamping screws DIN 912 MAT. 12.9 - Torque (CSTO) Nm | 14 |
| Extraction thread - Type (ETT) | M8 |
| Extraction thread - N. (ETN) | 4 |
| Weight (WEIGHT) kg | 0.27 |