


SIVACON, base, with cutouts for flanges, IPXX, T: 500 mm, W: 600 mm, zinc-plated

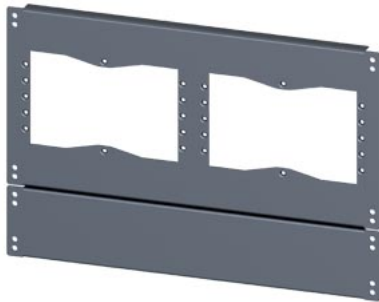

Model			
product brand name		SIVACON	
design of the product		With cut-outs for flanges	
design of the surface		zinc plated	
design of the product EMC version		No	
material		steel	
protection class IP		IPXX	
product component			
• ventilation		No	
Mechanical Design			
width		600 mm	
depth		500 mm	
net weight		3 200 g	
Approvals Certificates			
General Product Approval		Test Certificates	other



[Special Test Certificate](#)

[Miscellaneous](#)

[Confirmation](#)

other	Environment
-------	-------------


[Miscellaneous](#)



[Environmental Confirmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
 Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>
 Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1065-2UB52-0>
 Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/8MF1065-2UB52-0>
 Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1065-2UB52-0
 CAx-Online-Generator
<http://www.siemens.com/cax>
 Tender specifications
<http://www.siemens.com/specifications>

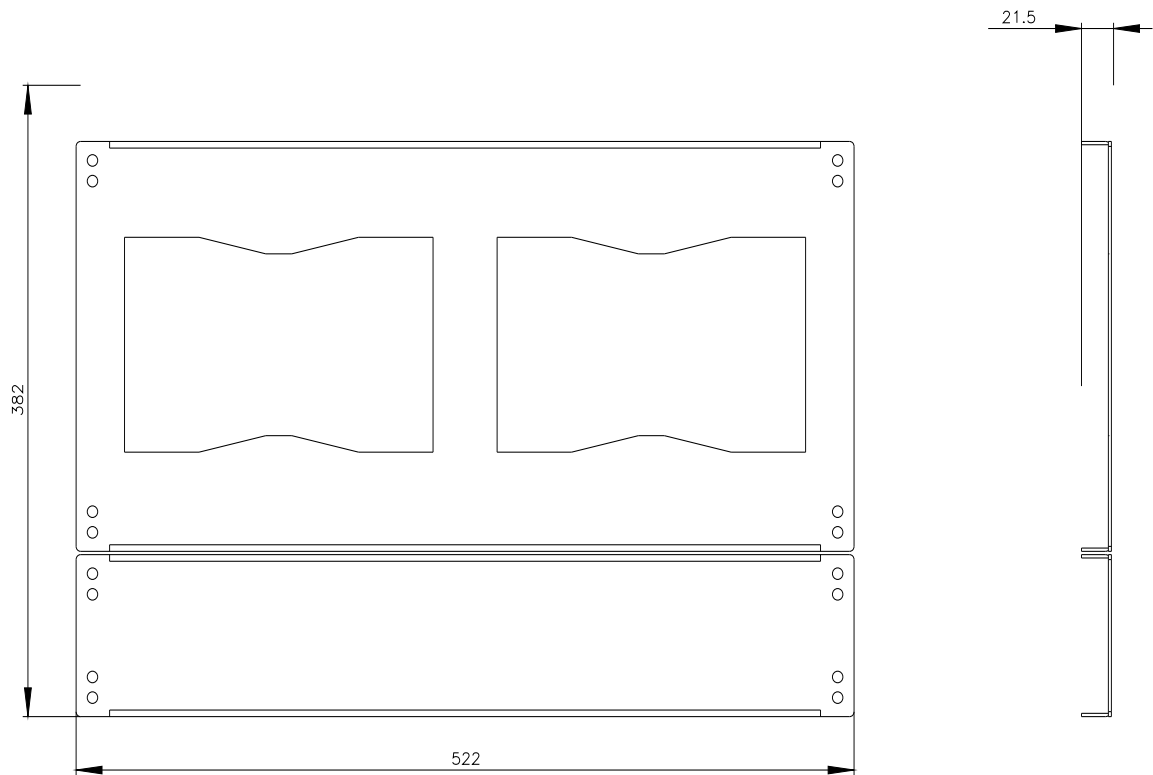

last modified:

6/3/2024 

