

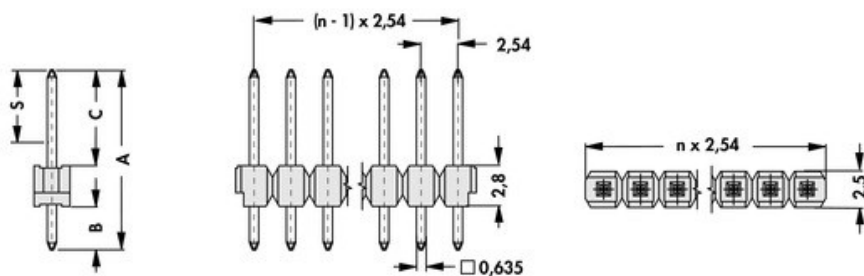
Data sheet Product SL 1 025 36 Z



PCB connectors>Male headers
one row, □ 0.635 mm

Features

pitch:	2.54 mm
no. of contacts:	36
contact material:	CuSn-alloy
surface of contact:	tin-plated
surface contact / contact sleeve:	• Ni+≥0.2μm Au • Ni+4...6μm Sn
version:	standard
volume resistance:	≤5 mΩ
nominal current:	3 A
nominal voltage:	250 V AC
test voltage:	2000 V
insulating body material:	PA 4.6. GF
temperature range:	• -40°C... +163°C • (260°C/10 s)
class of inflammability:	UL 94 V-0
specific insulation resistance:	>10 ⁷ Ω·m
connection type:	THT (soldering)
reflow solderable:	yes

Technical Drawing

A:	11.2 mm
B:	2.6 mm
C:	5.8 mm
S:	4.0 mm

Fischer Elektronik GmbH & Co. KG
DEUTSCHLAND • GERMANY • ALLEMAGNE

Nottebohmstraße 28
58511 Lüdenscheid

Telefon +49 2351 435-0
Telefax +49 2351 45754

info@fischerelektronik.de
www.fischerelektronik.de