

5

4

3

2

1

D

C

B

A



Description: BNC 3PC crimp for 8281

Part No: 27-9104

Application: For Belden 8281 Cable

Crimp Tool: 24-8861P

Impedance: 50 ohm

Frequency Range: 0~4 GHz

Material:

Body	Brass Nickel plated
Insulator	Delrin
Contact	Brass Gold plated
Sleeve	Brass Nickel plated
Coupling nut	Zinc Nickel plated

RoHS Compliance: Yes

Technical Detail: Refer to Emerson Document P/N 27-0000

DRAWING NO.
27-9104

REVISIONS

01	OFFICIAL RELEASE				Betty	2009.09.08 09:34:27 +08'00'
	08-18-09	L	L	T		

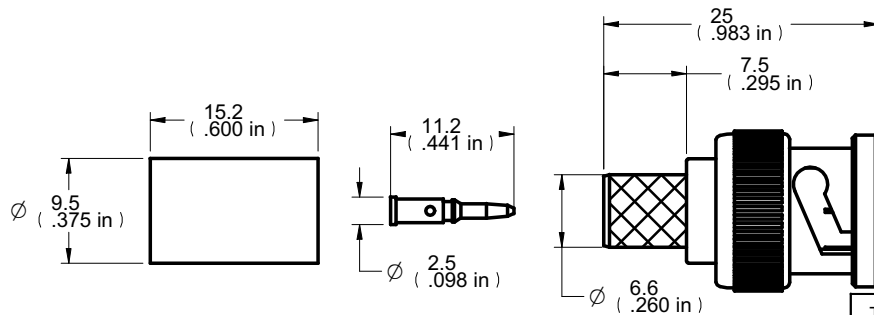
D

C

B

A

受控 CONTROLLED DOCUMENT					
编号 P/N	27-9104-C UST	版本 Rev	01	日期 Rel'd Date	SEP 14,09

**DIM OUTLINE****CUSTOMER COPY**

TOLERANCE UNLESS OTHERWISE SPECIFIED		DRAWN BY LINDA.WU	DATE 08-18-09
DECIMALS	mm	CHECKED BY LINDA.WU	DATE 08-18-09
X	± 0.5	APPROVED BY THOMAS	DATE 08-18-09
X.X	± 0.3		
X.XX	± 0.1		
ANGLES	± 0.5°	U/M	mm

THIS DRAWING WAS PRODUCED BY COMPUTER,
DO NOT SCALE DRAWING OR UPDATE MANUALLY.

 EMERSON Network Power		Connectivity Solutions	
TITLE			
BNC 3PC CRIMP FOR 8281			
SHEET 1 OF 1	DRAWING NO. 27-9104		SIZE A