


ENCLOSED HOSE REELS FOR COMPRESSED AIR / STEEL

DPF Series - Industrial type - Polyurethane hose



Part number	Length (m)	Flow rate (l/min)	Temperature min/ max (°C)	Max. operating pressure (bar)	Net weight (Kg)	Female thread	Profile
DPF 0815IS	15.00	500.00	-15.00 / 40.00	12.00	7,4	G3/8	ISO 6150B
DPF 1012IS	12.00	833.00	-15.00 / 40.00	12.00	7,3	G3/8	ISO 6150B
DPF 0815ES	15.00	500.00	-15.00 / 40.00	12.00	7,4	G3/8	EUROPEAN
DPF 1012ES	12.00	900.00	-15.00 / 40.00	12.00	7,23	G3/8	EUROPEAN
DPF 0815BS	15.00	500.00	-15.00 / 40.00	12.00	0	G3/8	BRITISH
DPF 0815CS	15.00	500.00	-15.00 / 40.00	12.00	7,38	G3/8	ISO 6150C
DPF 1012CS	12.00	833.00	-15.00 / 40.00	12.00	7,31	G3/8	ISO 6150C

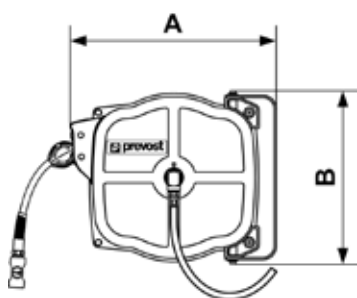

Part number	Dim. A (mm)	Dim. B (mm)	Ø int/ext (mm)
DPF 0815IS	377.00	317.00	8.00 / 12.00
DPF 1012IS	377.00	317.00	10.00 / 14.00
DPF 0815ES	377.00	317.00	8.00 / 12.00
DPF 1012ES	377.00	317.00	10.00 / 14.00
DPF 0815BS	377.00	317.00	8.00 / 12.00
DPF 0815CS	377.00	317.00	8.00 / 12.00
DPF 1012CS	377.00	317.00	10.00 / 14.00