




Technical data

GS87410

Thrust washer

Needle roller bearing, thrust needle roller bearing, outer ring

VISUAL (S)

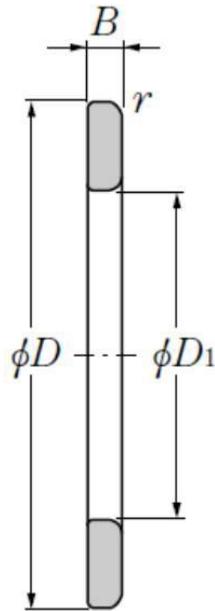

PRODUCT DEFINITION

Brand	NTN
D - Outside diameter of support washer OR - GS	110 mm
D1 - Bore diameter bearing washer OR - GS	52 mm
B - Ring thickness	9,5 mm
rs - Min fillet radius	1,5 mm
Bearing ring (outer ring) GS mass	0,56 kg

PRODUCT PERFORMANCE

Tmin - Min operating temperature	253,15 °K
---	-----------



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT PERFORMANCE

Tmax - Max operating temperature

393,15 °K

