


With 4 holes flange jack (type tightening)

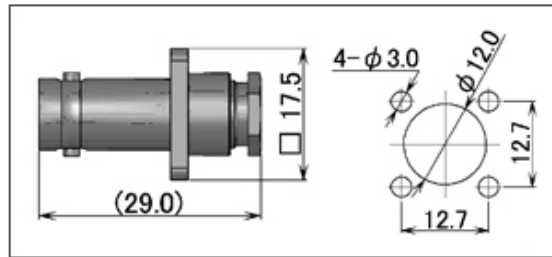

050-1432

RoHS指令対応

[図面を見る](#)

Applicable cable

3D-2V

How to Cable

A-1

050-1430

RoHS指令対応

[図面を見る](#)


Applicable cable

RG-58

How to Cable

A-1

PP straight adapter in series

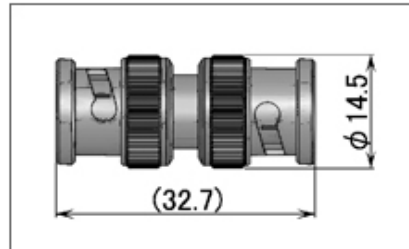

050-1440


RoHS指令対応

[図面を見る](#)

VSWR

DC ~ 2GHz: ≤ 1.3

JPJ adapter in series form T

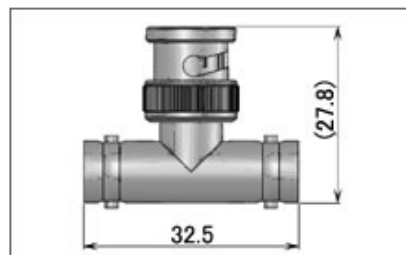


050-1460

RoHS指令対応

[図面を見る](#)

JJ T-shaped adapter in series

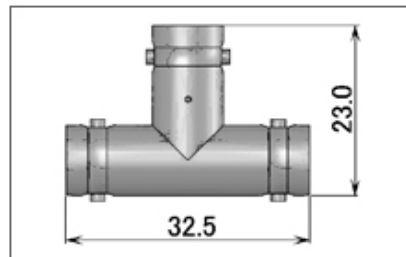


050-1470

RoHS指令対応

[図面を見る](#)

PJ L-shaped adapter in series

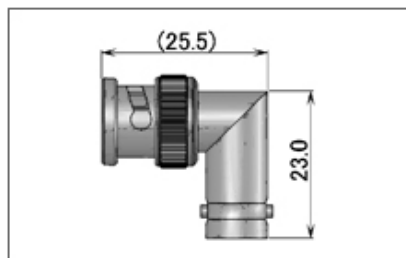

050-1480


RoHS指令対応

[図面を見る](#)

VSWR

DC ~ 2GHz: ≤ 1.4

Straight adapter in series JJ (Flanged)

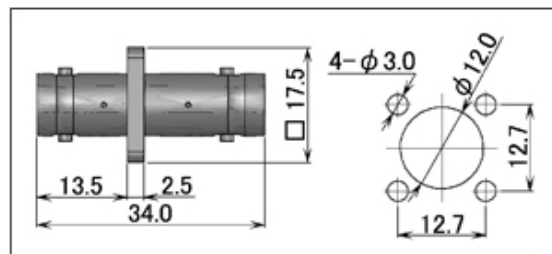

050-1484

RoHS指令対応

[図面を見る](#)


VSWR

DC ~ 2GHz: ≤ 1.3

Remarks

Flanged

Straight adapter in series JJ (Bulkhead type)

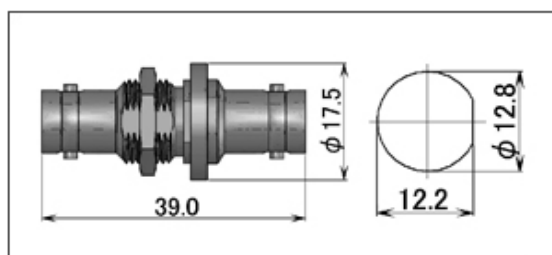

050-1486

RoHS指令対応


[図面を見る](#)

VSWR

DC ~ 2GHz: ≤ 1.3


Remarks

Bulkhead type

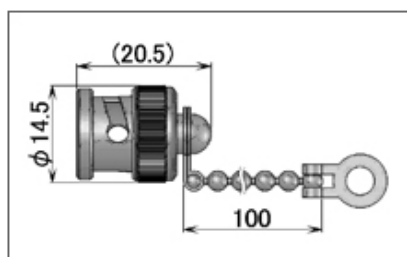

050-1494

RoHS指令対応

 図面を見る