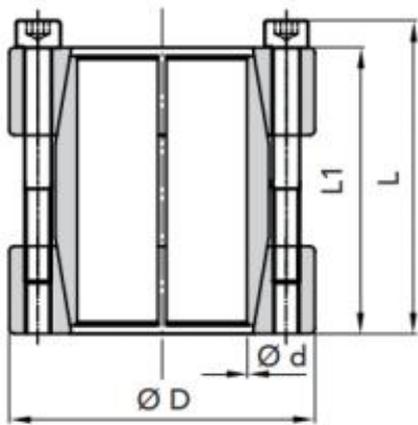


06950040

RCK 95 - Rigid joint

2D Technical Drawing

Dynamic 3D View
Technical Specifications

Part number (CODE)	06950040
Ød (DD) mm	40
ØD (D) mm	75
L1 (L1) mm	75
L (L) mm	83
Maximum torque Mt (MT) Nm	900
Clamping pressure - Shaft (CPS) N/mm ²	95
Clamping screws DIN 912 MAT. 12.9 - Num. (CSN)	4
Clamping screws DIN 912 MAT. 12.9 - Type (CST)	M8x60
Clamping screws DIN 912 MAT. 12.9 - Torque (CSTQ) Nm	41
Weight (WEIGHT) kg	1.40