

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

35725-5210

Status:

Active

Description:

6.35mm Tab Slip-On Wire-to-Wire Terminal, Female, 14-12 AWG, Tin-Plated

Documents:

Drawing (PDF)

Product Specification PS-35546-002 (PDF)

Packaging Specification PK-35725-005 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Terminals
Series	35725
Application	Power
Crimp Quality Equipment	Yes
Product Name	Tab and Receptacle
UPC	756054256343
Physical	
Gender	Female
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.746/g
Packaging Type	Reel
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	5.00mm max.
Wire Size AWG	12, 14
Wire Size mm²	N/A

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-35725-005
Product Specification	PS-35546-002
Sales Drawing	SD-35725-501

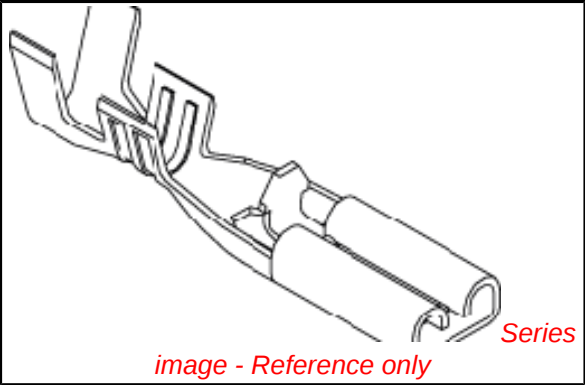


image - Reference only

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS

Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
35725Series

Mates With
6.35mm Tab

Use With
35546 , 35547

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Extraction Tool	0638132700

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION