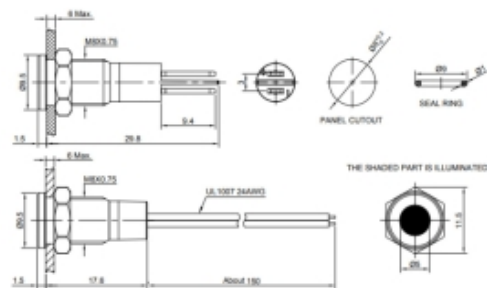


DX08LY024B Datasheet

Product Name // DX08LY024B, 8mm Diameter, Solder Lug, Yellow, 24V, Black Plated Brass

 [View Product Page](#)

// Product Description:

- | | |
|--|--|
|  DX Range |  Yellow |
|  8mm Diameter |  24V |
|  solder Lug |  Black Plated Brass |

// General Information:

Product Display Title:	8mm Vandal Resistant Indicator DX Range
Product Family:	Indicators
Product Series:	8mm Vandal Resistant Indicator DX Range
Bezel Finish:	Gloss
Body Colour:	Black
Body Material:	Brass
Body Material Type:	Metal
Diameter:	8mm
Dielectric Withstanding Voltage:	1500V
Function:	Vandal Resistant Indicator
Illumination Colour:	Yellow
Illumination Voltage:	24V
Indicator Profile:	Flat-round
Insulation Resistance:	≥100MΩ(500VDC)
Ip Rating:	IP67
Material Finish:	Gloss
Max Operating Temperature:	55°C
Min Operating Temperature:	-25°C
Max Panel Thickness:	6mm
Panel Cut Out:	8mm Diameter Circle
Rohs Compliant:	Yes
Thread Size:	M8 X 0.75

// Product PDF Links



6mm & 8mm Vandal Resistant...

// Product 3D CAD Model Links



DX08LY024B3D CAD Model