


Technical data

NUTR305/3AS

Roller follower with inner ring

Needle roller bearing, roller follower, full-complement cylindrical roller, with inner ring, double-side shields, spherical outer ring

VISUAL (S)

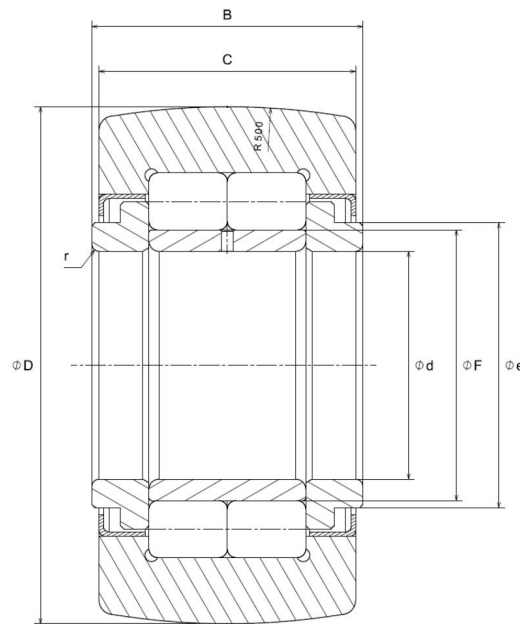

PRODUCT DEFINITION

Brand	NTN
d - Internal diameter	25 mm
D - External diameter	62 mm
C - Width of bearing, drawn cup or outer ring	24 mm
F - Under roller diameter	30 mm
B - Bearing/Inner ring width	25 mm
e - Inlet diameter of roller or washer	31 mm
R - Track roller radius	500 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION	
rs - Min fillet radius	0,3 mm
Bearing with/without cage	Sans
Radial clearance class	CN
Precision class	P0
Mass	0,45 kg

PRODUCT PERFORMANCE	
Cr - Dynamic load rating	42,5 kN
C0r - Static load rating	57,5 kN
Track load capacity spherical outer ring	6,95 kN
N lim - Grease lubrication limit speed	3300 tr/min
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	120 °C

ESHOPDONOTDISPLAY	
Tracepart	Oui/Yes
Reference	NUTR305/3AS
Image	NRBNUTR_1.jpg, NRBNUTR_3.jpg
Rolling element material	Acier 100Cr6

