


SIVACON, Roof, with Ventilation openings with Ventilation openings IP40, W: 800 mm, T: 500 mm, zinc-plated

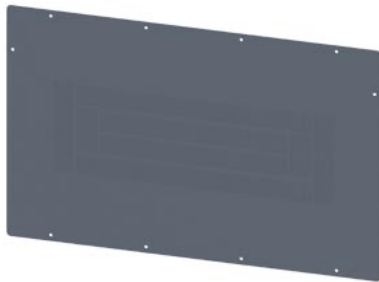

Model		
product brand name	SIVACON	
product designation	top plate	
design of the product	With ventilation openings	
design of the surface	zinc plated	
design of the product EMC version	No	
Protection class		
protection class IP	IP40	
Suitability		
suitability for use for outside use	No	
Product details		
product component		
• cable entry	No	
• ventilation	Yes	
Mechanical Design		
width	800 mm	
depth	500 mm	
ventilation cross section outlet can be used	430 cm²	
material	steel	
Approvals Certificates		
General Product Approval		Test Certificates
		other



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

other

Environment

[Miscellaneous](#)



[Environmental Confirmations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1085-2UD30-0A>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1085-2UD30-0A>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1085-2UD30-0A

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

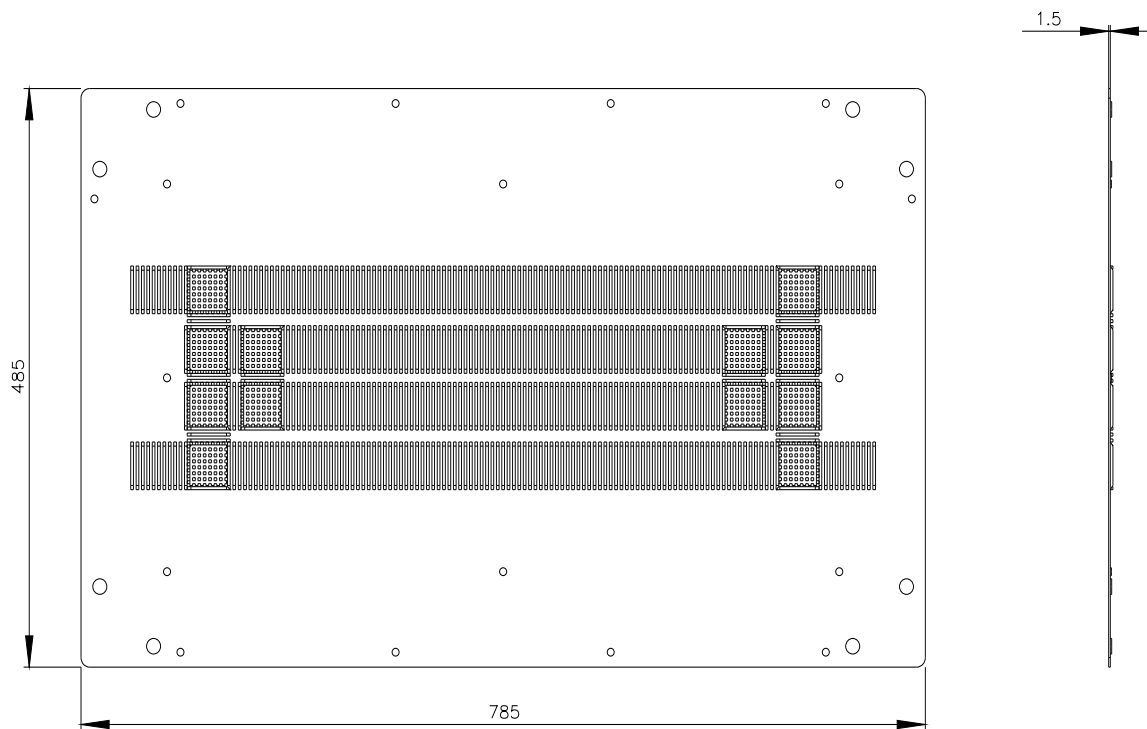

last modified:

1/16/2025 

