

Datasheet

## RS Pro P13.5s Filament Indicator Lamp, Clear, 2.8 V, 850 mA, 10h

RS Stock No: **104-963**



### Product Details

RS Pro P13.5s filament indicator lamp comes with clear lens and P13.5s prefocus base. It is filled with Krypton and Xenon gas for super-high brightness. It has a voltage rating of 2.8 V and current rating of 850 mA. The lamp has 10 h life.

### Features and Benefits

- Alternative to vacuum types
- P13.5s prefocus base
- Clear lens




**Specifications:**

Current Rating	850 mA
Diameter	9.3 mm
Lamp Base	P13.5s
Lamp Size	T9
Length	31 mm
Lens Colour	Clear
Life Hours	10 h
Luminosity	35 lm
Voltage Rating	2.8 V

RS Stock No.	104963
--------------	--------

*DRAWING - I*

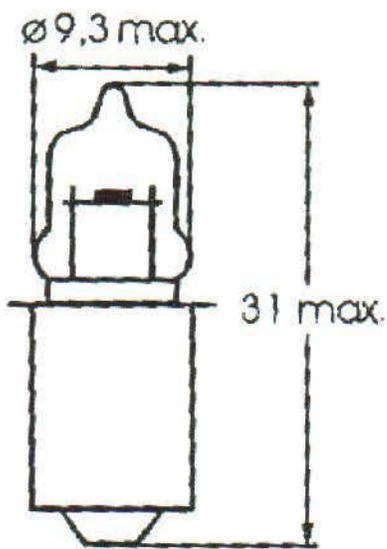

Unit : mm

1. Structure	Bulb Type	T9x28
	Bulb Diameter	Ø 9.3Max.
	Length	31.0Max
	Base Type	P13.5s
2. Design Characteristics	Voltage	2.8V
	Amperage	850mA±10%
	Gas Type	Halogen gas-filled
	Luminous Flux	35Lm±20%
	Life Hours	10Hrs