

Universal - AS*3*1F AS1311F-M5-06

Datasheet


General series information

- Port Size: M3, M5, 10-32 UNF, 1/8, 1/4, 3/8, 1/2
- Applicable Tubing O.D.: Ø 3.2 to Ø 12 mm and Ø 1/8" to Ø 1/2"
- Operating Pressure Range: 0.1 to 1 MPa.

Standard specifications

Size	1 (M3, M5 Basis)
Style	3 (Universal)
Control Method	1 (Meter-in)
Thread	M3, M5, U10/32, Rc
Port Size	M5 (M5X0.8)
Tube Size	Ø6
Option	None
Fixed Orifice	None
Made to Order	None
Lock Nut	Standard (Hexagon)
Weight	0.007 Kg

Dimensions

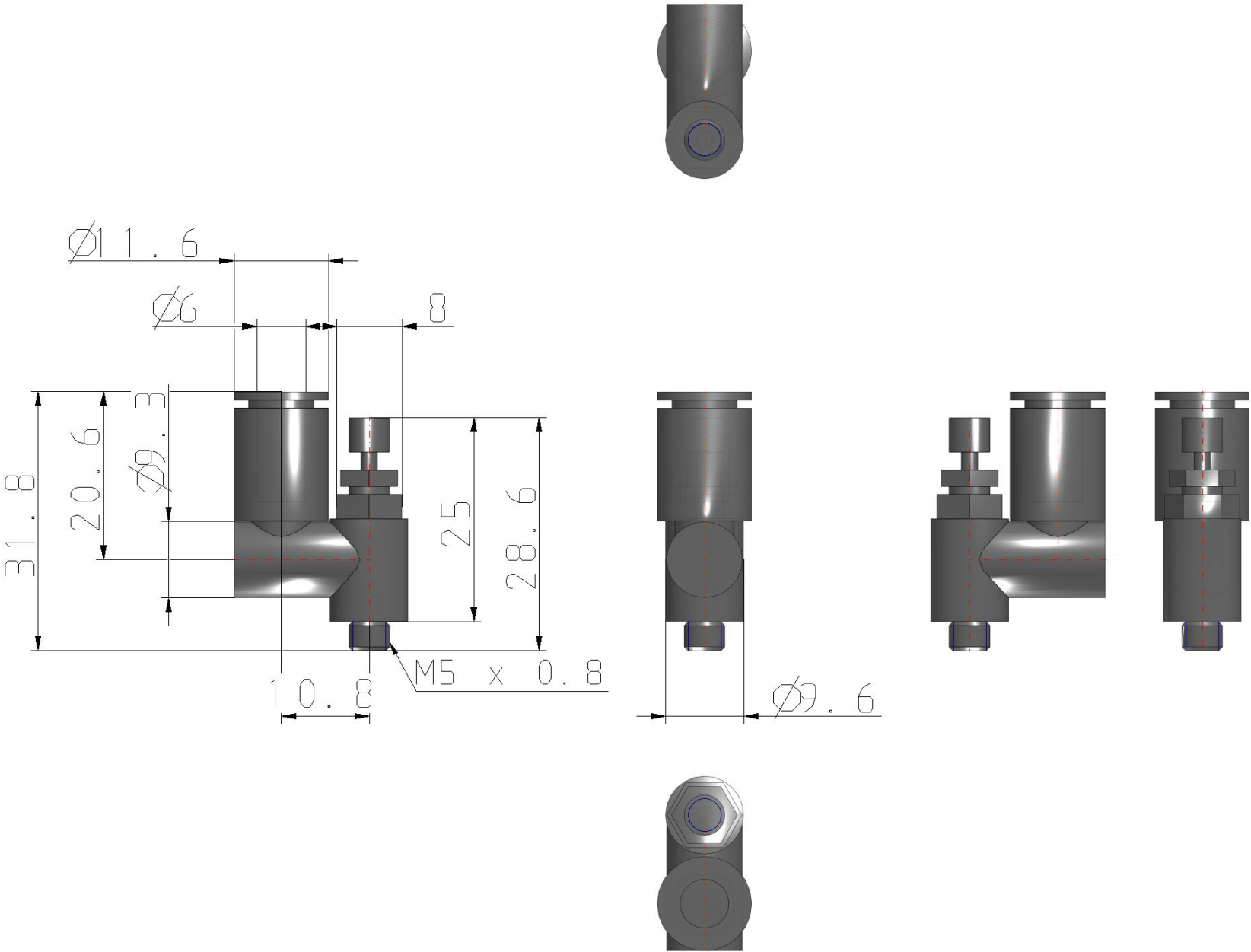

Additional information

Catalogue

[AS_2-3_1F-A_EU.pdf](#)