

RIGI™

SWISS ONE
SAFETY

The best seller of the coming decade.. !

Whatever your workplace environment, Rigi™ delivers the perfect association of performance, safety and active style.

The unique close fitting design, ultra light weight... 19gr of comfort and fit. wide field of vision and a design fitting all faces...

The ergonomic fit with Flexofit™ temples, flat and thin compatible with any eardefender or helmet. Those features enable wearers to achieve a comfortable customised fit, throughout the day. Try it... adopt it!

Available in a wide range of lens versions... Anti-scratch, Excellence coating and a unique selection of Blue Blocker lenses.

WEIGHT

19g

LENS

- Large field of vision
- Wide range of lenses
- Optimal coverage




FRAME

- Ultra lightweight
- Flex Flat, thin temple
- Pressure free



- + FLEXOFIT™ TECHNOLOGY
- + ONE FITS ALL
- + WRAPAROUND DESIGN

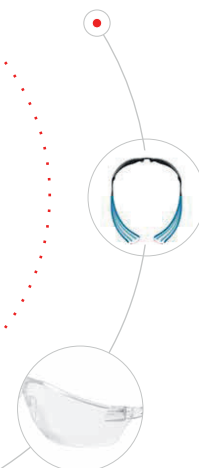

1RIG21C
Clear



1RIG21S
Smoke



1RIG23C Clear
1RIG23CKN Clear



1RIG23S Clear
1RIG23SKN Smoke



1RIG23IO



1RIGLABB21AR
BLUE BLOCKER
30% filtration



1RIGBB21AR
BLUE BLOCKER
30% filtration



1RIGBB21LO
BLUE BLOCKER
60% filtration



1RIGBB21LB
BLUE BLOCKER
60% filtration

Reference	Lens Markings	Frame Markings	Lens Treatment	Conformity
1RIG21C	2C-1,2 1 FT CE	EN 166 FT CE	Anti-scratch	EN 166 EN 170
1RIG21S	5-2,5 1 FT CE	EN 166 FT CE	Anti-scratch	EN 166 EN 172
1RIG23C	2C-1,2 1 FT CE	EN 166 FT CE	Anti-scratch / Anti-fog	EN 166 EN 170
1RIG23S	5-2,5 1 FT CE	EN 166 FT CE	Anti-scratch / Anti-fog	EN 166 EN 172
1RIG23IO	5-1,7 1 FT CE	EN 166 FT CE	Anti-scratch / Anti-fog	EN 166 EN 172
1RIG23CKN	2C-1,2 1 FTKN CE	EN 166 FT CE	Anti-scratch / Anti-fog (KN)	EN 166 EN 170
1RIG23SKN	5-2,5 1 FT KN CE	EN 166 FT CE	Anti-scratch / Anti-fog (KN)	EN 166 EN 172
1RIGLABB21AR	2C-1,2 1 FT CE	EN 166 FT CE	Anti-scratch	EN 166 EN 169
1RIGBB21AR	2C-1,2 1 FT CE	EN 166 FT CE	Anti-scratch	EN 166 EN 169
1RIGBB21LO	2C-1,4 1 FT CE	EN 166 FT CE	Anti-scratch	EN 166 EN 168
1RIGBB21LB	2C-1,4 1 FT CE	EN 166 FT CE	Anti-scratch	EN 166 EN 167

Conforms to
EN 166: 2001

For Lens & frames markings details, please refer to pages 7 to 9 in Swiss one catalogue.

For Lens technologies and colors details please refer to pages 10 to 12 in Swiss one catalogue.

Swiss One Safety, OX29 OTA UK - Technical helpline: +44(0)1993 826051 - email: technical@swissonesafety.net

RIGI™

SWISS ONE
SAFETY

DIMENSIONS OF SPECTACLE

Lens Thickness:	1.8mm
Lens Base:	9.5
Lens Size (Diagonal):	70.5mm
Bridge:	-
Temple Length (Lens to tip):	162.0mm
Overall Width:	133.0mm
Closest point between temple tips:	31 +/- 3mm

INSTRUCTIONS FOR USE

- In use ensure that the safety spectacles fit comfortably and securely on the head
- Ensure that the safety spectacles are in place, before entering the hazard area

CLEANING & MAINTENANCE

- The safety spectacles may be cleaned with soap and warm water and dried with a soft cloth
- Do not clean with chemical or abrasive cleaners
- The eye shield should be stored out of direct sunlight, away from chemicals and not exposed to extremes of temperature

LIMITATIONS OF USE

- Protection will only be offered if the safety spectacles are fitted correctly
- If the safety spectacles become scratched or damaged they should be replaced, likewise if the safety spectacles are subjected to severe impact they should be replaced immediately
- Do not apply paint, solvents, adhesives or self-adhesive labels, except in accordance with instructions from the manufacturer
- The safety spectacles, when in contact with the skin may cause allergic reactions to susceptible individuals. If this occurs leave the hazard area, remove the eye shield and seek medical advice
- The attention of users is also drawn to the dangers of modifying or removing any of the original component parts, other than as recommended by the manufacturer
- Rigi™ is not suitable for protection against dusts, liquids or molten metals



- 1 Polycarbonate
2 Polycarbonate

- 3 PC/ TPE
4 PC/ TPE

DIMENSIONS OF INNER PACKAGING

Quantity:	10
Weight:	0.48kg




H Height: 96mm

L Length: 191mm

W Width: 284mm

DIMENSIONS OF OUTER PACKAGING

Quantity:	300
(30 display boxes of 10 p)	
Weight: (Approx.)	16.4kg

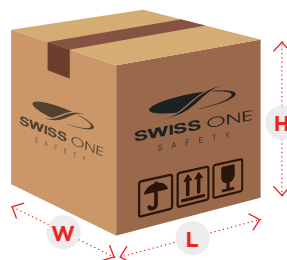

H Height: 63mm

L Length: 98.5mm

W Width: 30mm

Reference	EAN barcode Unit	EAN barcode inner packaging	EAN barcode outer packaging	Country of origin
1RIG21C	5038428303002	5038428303019	5038428303026	Taiwan
1RIG21S	5038428303033	5038428303040	5038428303057	Taiwan
1RIG23C	5038428255097	5038428255103	5038428255103	Taiwan
1RIG23S	5038428255066	5038428255073	5038428255080	Taiwan
1RIG23IO	5038428311168	5038428311175	5038428311182	Taiwan
1RIG23CKN	5038428303064	5038428303071	5038428303088	Taiwan
1RIG23SKN	5038428303095	5038428303101	5038428303118	Taiwan
1RIGLABB21AR	5038428303125	5038428303132	5038428303149	Taiwan
1RIGBB21AR	5038428303156	5038428303163	5038428303170	Taiwan
1RIGBB21LO	5038428303187	5038428303194	5038428303200	Taiwan
1RIGBB21LB	5038428303217	5038428303224	5038428303231	Taiwan