

1M USB A to Lightning Cable - Durable 90 Degree Right Angled Black USB Type A to Lightning Connector Sync & Charger Cord w/Aramid Fiber Apple MFI Certified iPad iPhone 11

Product ID: RUSBLTMM1MBR



This angled USB to Lightning cable withstands the demands of charging and syncing your mobile devices. Tested for strenuous wear and tear, the Lightning cable's angled connector gives you easy access to your mobile device even while charging.


Built for Daily Use

With Kevlar® aramid fiber reinforcement, the durable Lightning cable is sheltered from the stress of frequent bends and twists, which allows the cable to flex without over-stretching.



Cable Key Features

- 1. Aramid fiber adds strength and durability to the cable
- 2. Insulated conductors reduce friction, provide more flexibility
- 3. EMI (electromagnetic interference) protection with aluminum-mylar foil and braided shielding
- 4. TPE (thermoplastic elastomer) cable jacket is softer and more flexible than a standard PVC cable

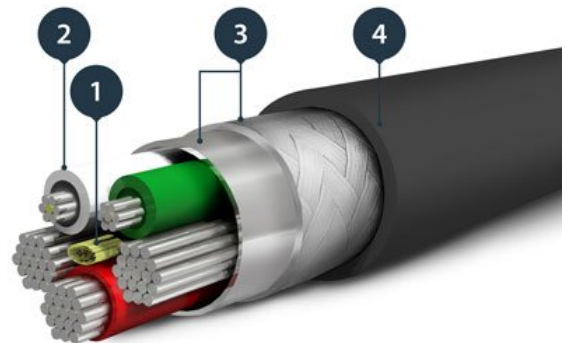

Flexible Strain Relief

Constructed to prevent the connector from separating from the cable jacket, the extra-long strain relief molding is tested to withstand over 10,000+ bend cycles at a 180° angle.



Connector Key Features

- 1. Lightning connector provides 12W for charging your iOS devices
- 2. Metal shield protects circuit board from EMI and reinforces the connection point
- 3. Strain relief tested to tolerate over 10,000+ bend cycles at a 180-degree angle

RUSBLTMM1MBR is an Apple MFi certified Lightning cable backed by a StarTech.com 2-year warranty.

Note: DuPont™ and Kevlar® are trademarks or registered trademarks of E.I. du Pont de Nemours and Company.



Certifications, Reports and Compatibility



Made for



iPhone | iPad

Applications

- Charge and sync your Lightning mobile devices
- Text, work, or game without the cable getting in the way
- Easy access in both portrait and landscape mode

Features

- **DURABLE:** USB A to lightning cable w/Kevlar aramid fiber for high tensile (pull) strength increasing reliability & cable life. Tested to withstand 10000+ bend cycles at 180° angle & 5000+ insertions
- **FLEXIBLE CABLE:** Built w/TPE jacket to absorb the stress of frequent bends while protecting the cable core. Durable wire & connector shields rugged charging cord from wear & tear of frequent in-car use
- **RIGHT ANGLED CONNECTOR:** Eliminates tension & protects the lightning port of iPhone 11 Pro, iPhone 11, iPhone XR, iPad Air, iPad, iPad Mini. Ideal for car mounts, classroom desk mounts or mounted POS
- **APPLE MFI CERTIFIED:** Fast & reliable charge from USB-A charger/port to lightning devices including AirPods, Magic Keyboard, Magic Trackpad, Magic Mouse. Supports USB 2.0 480 Mbps data transfers
- **CABLE SPECS:** Length: 1m (3ft) | Color: Black | Connectors: Angled Lightning to USB-A | Performance: USB 2.0 | Reinforcement: Aramid Fiber | Jacket Type: TPE | Shielding: EMI Protection | Warranty: 2Yr

Hardware	Warranty	2 Years
	Cable Jacket Type	TPE - Thermoplastic Elastomers
	Cable Shield Type	Aluminum-Mylar Foil with Braid
	Connector Plating	Nickel
Performance	Type and Rate	USB 2.0 - 480 Mbit/s
Connector(s)	Connector A	1 - USB Type-A (4 pin) USB 2.0 Male
	Connector B	1 - Apple Lightning Connector (8-pin) Male
Physical Characteristics	Cable Length	3.3 ft [1 m]
	Color	Black
	Connector Style	Angled
	Product Height	2 in [5 cm]
	Product Length	3.3 ft [1 m]
	Product Width	5.3 in [135 mm]
	Weight of Product	0.9 oz [26 g]
	Wire Gauge	22/32 AWG
Packaging Information	Package Height	6.3 in [160 mm]
	Package Length	5.7 in [14.5 cm]
	Package Width	3 in [75 mm]
	Shipping (Package) Weight	0.1 lb [0 kg]
What's in the Box	Included in Package	1 - 1 m Lightning Cable

Product appearance and specifications are subject to change without notice.