


1748-BP

Insertion nylon cable ties, natural colour

CE

Material: polyamide PA 6.6
 Self-extinguishing class: UL 94-V2
 Working temperature: -40 °C ÷ +85 °C
 Minimum installation temperature: -10 °C
 Resistance to chemicals: Good resistance to bases, oils, greases, chloride solvents. Limited resistance to acids. Not resistant to phenols
 Reference standards: EN 62275:2015-02
 Classification: type 1 (EN); type 21 (UL)

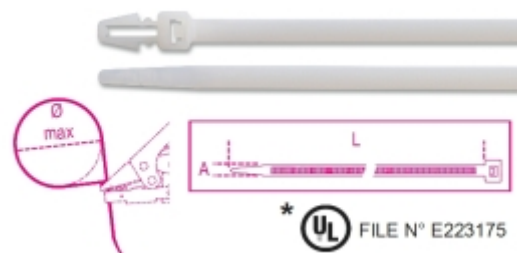

Please indicate number of cable ties, and not of packages, in your order

		art.	A mm	L mm	Ø MAX mm	F MAX N	B mm
	BMBP1536	BMBP1536	3.6	155	37.9	180	6
*	BMBP2048	BMBP2048	4.8	200	50.8	230	8