


FEATURES

- **Nylon Material:** Provides durability and resistance to wear and tear.
- **UL 94 V-0 Fire Behaviour:** Ensures high flame retardancy for safety in critical environments.
- **Length of 100mm:** Suitable for bundling medium-sized cable groups.
- **Maximum Bundle Diameter of 22mm:** Accommodates a wide range of cable sizes.
- **Tensile Strength of 8kg:** Offers strong holding capacity to prevent slippage.
- **Non-Releasable Design:** Ensures a permanent and secure hold.
- **RoHS Compliant:** Meets environmental and safety standards.

RS PRO 100mm Nylon Cable Tie, UL 94 V-0

RS Stock No: 656-033

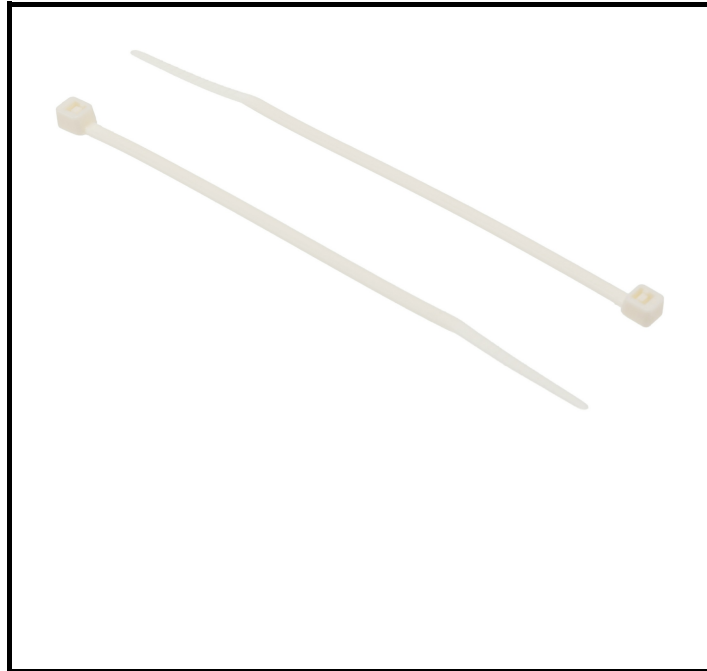

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

RS PRO offers a reliable solution for securing cables and wires with its 100mm Nylon Cable Tie. Designed for non-releasable applications, this cable tie ensures a secure and permanent bundling of cables, making it ideal for various industrial and domestic uses.

General Specifications

Colour	White
Product Type	Cable Tie
Sub Type	Non-Releasable
Tensile Strength	8 kg

Protection Category

Fire Behaviour	UL 94 V-0
UV Resistant	No

Mechanical Specifications

Length	100 mm
Material	Nylon
Maximum Bundle Diameter	22 mm
Width	2.5 mm

Operation Environment Specifications

Maximum Operating Temperature	85 °C
-------------------------------	-------

Approvals

Standards/Approvals	RoHS, UL94V-0
---------------------	---------------

