

MLFB-Ordering data

6SE6400-3TC07-5ED0

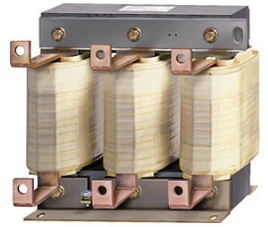


Figure similar

Client order no. :

Order no. :

Offer no. :

Remarks :

Item no. :

Consignment no. :

Project :

Rated data		Connections	
Rated current	90.00 A	Power connection Power Module	
Power loss	0.277 kW	Version	flat connector for cable lug M6
Mechanical data		Power connection motor	
Width	270.0 mm (10.63 in)	Version	Flange connection for cable lug M6
Height	248.0 mm (9.76 in)	Max. motor cable length	
Depth	188.0 mm (7.40 in)	3 AC 380 V -10 % ... 400 V	
Degree of protection	IP00	Shielded	200 m
Net weight	26.70 kg (58.86 lb)	Unshielded	300 m
		3 AC 401 V ... 480 V +10 %	
		Shielded	200 m
		Unshielded	300 m
		PE connection	
		Version	M6 screw