


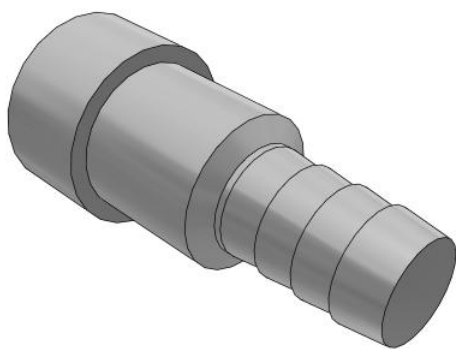

KK130S-*B, S-Couplers, Barb Fitting KK130S-13B

Datasheet


General series information

- Barb Fitting.
- Hose Nominal: 1/4, 3/8, 1/2.

Standard specifications

Type	S (Socket)
Hose Nominal	ø12 (ø1/2")
Pressure medium	Air
Maximum operating pressure	1.5 MPa
Minimum operating pressure	0 MPa
Proof pressure	2 MPa
Maximum ambient temperature	80 °C
Minimum ambient temperature	-20 °C (No freezing)
Sealing principle	Male thread with sealant
Plating	Sleeve: Electroless nickel plated Other external metal parts: Zinc chromated
Weight	0.083 Kg

Dimensions

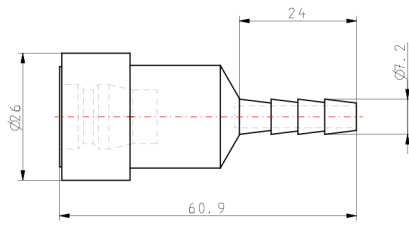

Additional information

Catalogue

[KK130-B_EU.pdf](#)