


Blue Elastic Rubber Trolley Wheel 100mm, 150kg

Elastic Rubber-tyred wheel

PRODUCT

Article number

571-411-10OR12

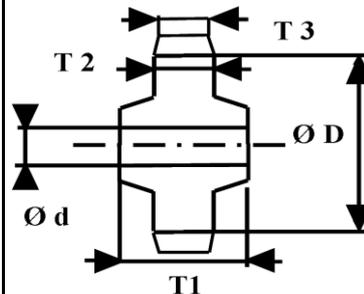

Product Details

Wheel Rim : very thick black polyamide.
 Tyre : solid, blue bonded elastic rubber tyre, non marking.
 Hub : symmetrical, roller bearing.

Specifications

Wheel Diameter - ØD ± 1%	100 mm
Hub Type	Roller Bearing
Hub Length T1	45 mm ±1
Width of Tread T2	36 mm ±1
Width of Tread-on floor T3	32 mm ±1
Axle Hole Ø d	Ø 12 mm
Hardness of tread A ±4	A 70 Shore
Load capacity	150 Kg
Temperature	-20 / +60 °C

TECHNICAL DATA

Applications :

Sensitive materials handling on uneven surfaces.
 Resilient with a low starting effort.
 Does not leave scratches or other marks on surfaces.
 Reduce shock and vibration.
 Quiet in use and high wear resistance.