


connecting cable

NEBS-L1G4-K-2.5-LE4

Part number: 572576

FESTO

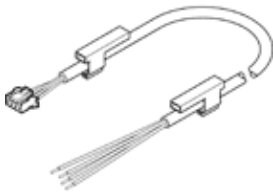

Data sheet

Feature	Value
Electrical connection 1	Socket, rectangular design L1, 4-pin
Electrical connection 2	Open end, 4-wire
Operating voltage range DC	0 ... 30 V
Acceptable current load at 40°C	1 A
Surge strength	0.8 kV
Cable length	2.5 m
Cable attribute	Standard
Test conditions of cable	Bending strength according to Festo standard Test conditions on request
Cable diameter	4.1 mm
Cable structure	4x0,14
Nominal conductor cross-section	0.14 mm ²
Colour code, core insulation	blue brown Black white
Protection class	IP40
Ambient temperature	-20 ... 60 °C
Ambient temperature with flexible cable installation	-5 ... 60 °C
Materials note	Free of copper and PTFE Conforms to RoHS
Degree of contamination	2
Corrosion resistance classification CRC	4 - Very high corrosion stress
Material cable sheath	PVC
Cable sheath colour	Grey
Material housing	PA
Material insulation	PP