




LED FIL T38X150 E27 DIM 12W (131W) 2100lm 830 Clear

Article number: 147034

BAI LED Filament Tube T38x150mm E27 220-240V 12W (131W) 2100lm 3000K Dimmable Clear FLOS LED-lamp

LED Filament Bulbs: Classic Look, Modern Efficiency. LED filament bulbs are the modern, eco-friendly alternative to traditional incandescent bulbs. Featuring filament technology, they use significantly less energy and have a much longer lifespan. This series of tubular bulbs is dimmable* and is ideal for replacing incandescent bulbs over 100W. They shine especially in elegant fixtures such as those by FLOS (like the iconic Glo-Ball). Dimmability depends on the type of dimmer and the number of bulbs per dimmer.

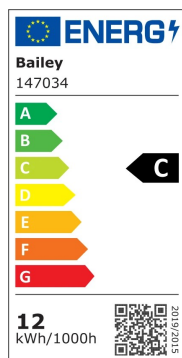

General ETIM properties


ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED FIL T38X150 E27 DIM 12W (131W) 2100lm 830 Clear
Brand	Bailey
Productseries	LED Filament tube
Producttype	T38X150 E27 830 CL

ETIM specifications

Socket	E27
Luminous flux [lm]	2100 - 2100
Nominal voltage [V]	230 - 230
Lamp power [W]	12 - 12
Colour temperature [K]	3000 - 3000
Diameter [mm]	38
Length [mm]	150
Dimmable	Yes
Lamp shape	Tube, single-ended
Beam angle [°]	320 - 320
Colour	White
Type of glass/cover	Clear
Lamp designation	Other
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	Yes
Rated luminous flux according to IEC 62612 [lm]	2100
Power factor	0.9
Lamp efficacy [lm/W]	175
Nominal current [mA]	53 - 53
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	Colourless
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	12
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG0
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	Yes
Dimming phase cut-on (leading edge)	Yes
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	C
With twilight switch	No
Material of light bulb	Glass

 Complementary articles



144482

Stand Floor Lamp E27 Black

Predecessor



145068

LED FIL T38X150 E27 DIM 14W
(145W) 2350lm 830 Clear