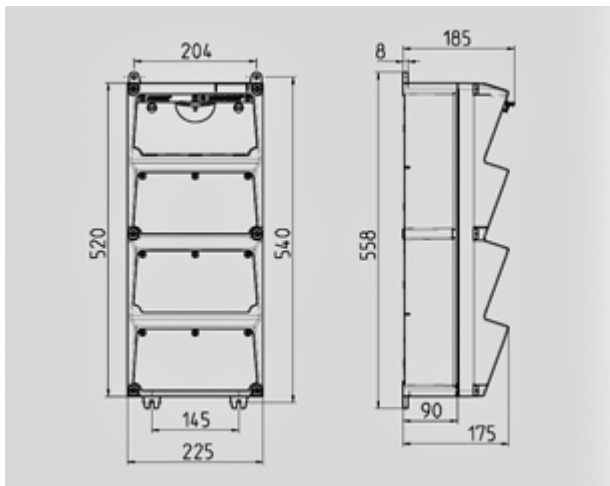


AMAXX® combination unit - Part no. 940009


- pre-wired for installation
- hinged to the side
- enclosure and insert made of AMAPLAST
- fusing behind a transparent cover

Protection type	IP 44
Fitted with	1 CEE 63A, 5p, 400V 1 CEE 32A, 5p, 400V 1 CEE 16A, 5p, 400V 2 SCHUKO® 16A, 230V
Fusing	1 Neozed D02, 3p 1 Neozed D01, 3p 2 Neozed D01, 1p
InA	63 A
RDF	0,8
Connection/feeder cable for 2 cables up to 5 x 25 mm ²	
Enclosure size	520 x 225 mm (H x W)


Drawing 1 MB 523

Depth dimensions at various fittings.

Sockets	Degrees	Depth
SCHUKO® 16A, 230 V	IP 44	186 mm
	IP 67	208 mm
CEE 16A, 3p, 230V	IP 44	216 mm
	IP 67	220 mm
CEE 16A, 5p, 400V	IP 44	222 mm
	IP 67	226 mm
CEE 32A, 5p, 400V	IP 44	231 mm
	IP 67	236 mm
CEE 63A, 5p, 400V	IP 44	260 mm
	IP 67	260 mm

Cable entries: closed for cut out. 2 x M 40 each on top and bottom, 2 x M 20 each on top and bottom for cut out.