


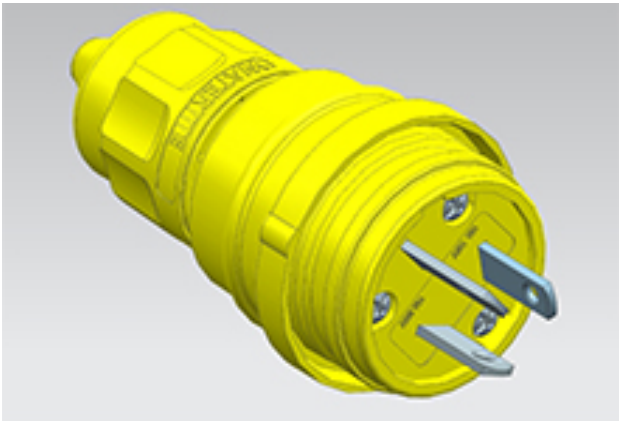

Part Number : [1301460015](#)
Product Description : Watertite Extreme Plug,
3 Pole/3 Wire, Non-NEMA, 15A/125V,
10A/250V, Cord Grip Body Size F2, Silicone
Husk
Series Number : 130146
Status : Active
Product Category : Wiring Devices
Engineering Number : 14W07



Documents & Resources

Drawings
[1301460015_sd.pdf](#)

3D Models and Design Files
[1301460015_stp.zip](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Relevant
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Not Relevant

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration

- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Wiring Devices
Series	130146
Description	Watertite Extreme Plug, 3 Pole/3 Wire, Non-NEMA, 15A/125V, 10A/250V, Cord Grip Body Size F2, Silicone Husk
IP Rating	IP69K
NEMA Configuration	Non-NEMA
Product Name	Watertite Extreme
Specialty	N/A
Type	Plug
UPC	78678871080

Agency

CSA	LR6837
-----	--------

Electrical

Current - Maximum per Contact	15.0A
GFCI	No
Voltage - Maximum	250V

Physical

Cord Grip Body Size	F2 1/2"
Cord Type	N/A
Flange	No
Flip Lid	No
Gender	Male
Length	N/A
Lighted Connector	No

Locking Blade	No
Net Weight	126.098/g
Poles	3-pole/3-wire
Receptacle Type	N/A

This document was generated on Mar 27, 2025