






ENGLISH

# Datasheet

## Thermally Conductive Gap Filler

RS Stock number 707-4718

1.4W/mK, 150x150x0.18mm, 1-side 3M 467 p.s.a

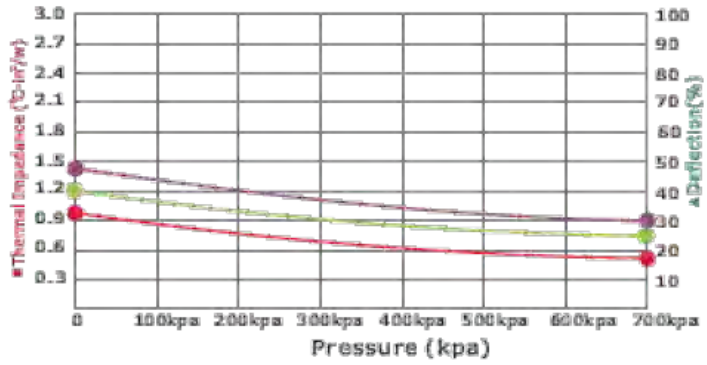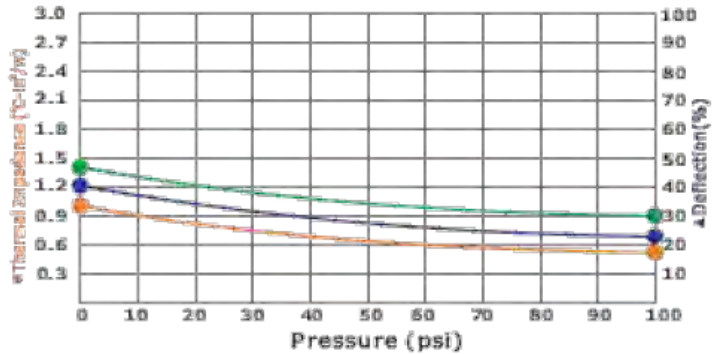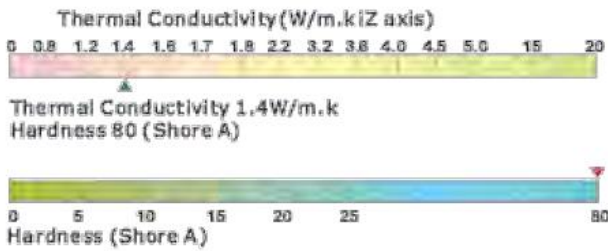

### Features

- Carrier: Fibreglass
- Good thermal conductivity
- Soft & high compressibility

Property		Unit	Tolerance	Test
Colour	Yellow	-	-	Visual
Thickness (gap to 0.1mm)	0.25/0.3/0.45	mm	-	ASTM D374
	0.0098/0.0118/0.0177	inch	-	ASTM D374
Thermal Conductivity	1.4	W/m.k	-	ASTM D5470
Flame Rating	V-0	-	-	UL94
Insulation Strength	3/4/5	kv/mm	-	ASTMD149
Weight Loss	<1	%	-	ASTM E595
Specific Gravity	2.0	g/cm³	±0.2	ASTM D792
Working Temperature	-40 ~ +200	°C	-	-
Volume Resistance	10 <sup>13</sup>	ohm-cm	-	ASTM D257
Elongation	5	%	±13	ASTM D412
Tensile Strength	150	Kgf/cm²	±2	ASTM D412
Standard Shape	-	Sheet ones	-	-
Hardness	80	Shore A	±5	ASTM D2240
REACH Compliant	Yes	RoHS Compliant	Yes	Yes