

Extended-nose pliers

402.MT

▷ ISO 9655, DIN ISO 9655, NF ISO 9655.

- For extra power.

ΔΔ : 76 g.





Rigid long-nose pliers

422.MT

▷ ISO 9655, DIN ISO 9655, NF ISO 9655.

ΔΔ : 70 g.

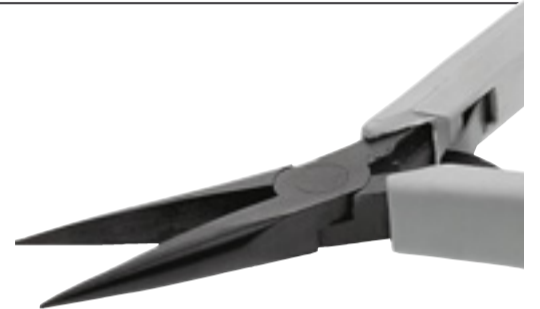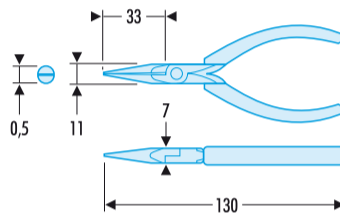


Short-nose pliers

432.MT

▷ ISO 9655, DIN ISO 9655, NF ISO 9655.

- Slim joint.

ΔΔ : 55 g.

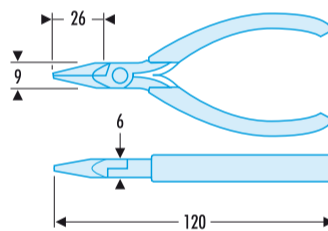


Snipe-nose pliers

432.LMT

▷ ISO 9655, DIN ISO 9655, NF ISO 9655.

- Slim joint for precision work.

ΔΔ : 65 g.

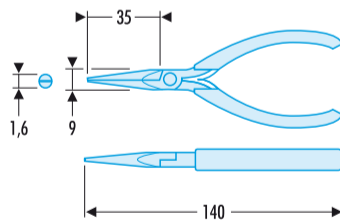

Extended-nose 40° pliers

403.MT

▷ ISO 9655, DIN ISO 9655, NF ISO 9655.

- For extra power.

ΔΔ : 75 g.

