

 

branching module FRM-H-D-MAXI

Part number: 170689
Classic

FESTO

Pneumatic manifold with 4 connections, attachment facility for auxiliary modules, without threaded connection plates with FRB threaded pin.

Modern alternatives can be found by entering the first four characters of the type code in the search field.

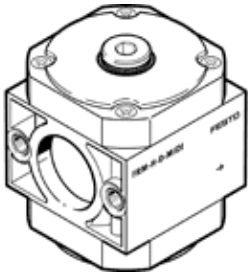

Data sheet

Feature	Value
Assembly position	Any
Design structure	Branching module
Operating pressure	0.25 ... 16 bar
Standard nominal flow rate in main flow direction 1->2	13,500 l/min
Maritime classification	see certificate
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Inert gases
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Storage temperature	-10 ... 60 °C
Air purity class at output	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Inert gases
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Product weight	446 g
Pneumatic connection, port 3	G3/4
Pneumatic connection, port 4	G1/4
Materials note	Free of copper and PTFE Conforms to RoHS
Material housing	Zinc die-casting