


# connecting cable NEBV-S1WA44-K-5-N-LE44-S9

Part number: 575421

FESTO

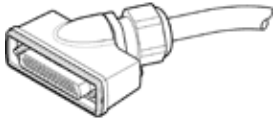

## Data sheet

Feature	Value
Mounting type	4-40UNC
Assembly position	Any
Product weight	860 g
Electrical connection	Plug socket Sub-D 44-pin
Operating voltage range DC	<= 30 V
Acceptable current load at 40°C	0.86 A
Cable length	5 m
Cable attribute	For static applications
Min. cable bending radius	122 mm
Cable diameter	10.2 mm
Cable diameter tolerance	± 0,3 mm
Cable structure	44x0,14
Protection class	IP65 IP67 in assembled condition
Ambient temperature	-5 ... 80 °C
Materials note	Conforms to RoHS
Degree of contamination	3
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Material cable sheath	PVC
Material housing	PA66-GF30
Material electrical contact	Bronze Gold plated