

Premium Performance with New 150mm 3M™ Hookit™ Back-up Pad System



 

The new Hookit range of back-up pads has been designed to give optimal abrasive disc performance in all sanding applications. A new, lower-profile pad design gives improved flexibility whilst maintaining a flat, rigid pad centre.

- Ultra efficient 'Direct Flow' extraction channels
- 150mm pads in 5/16" or M8 attachment
- Optimum weights - balanced for minimum vibration in use
- Useable with 6 and 9 hole abrasive discs
- Tough, high foam-cell density
- Choice of colour coded standard and soft flexibility versions
- Co-moulded (one piece) premium quality construction

New 3M™ Hookit™ Back-up Pad System

New Look

Tampo-graph printing to ensure you use the correct Back-up Pad for every application.

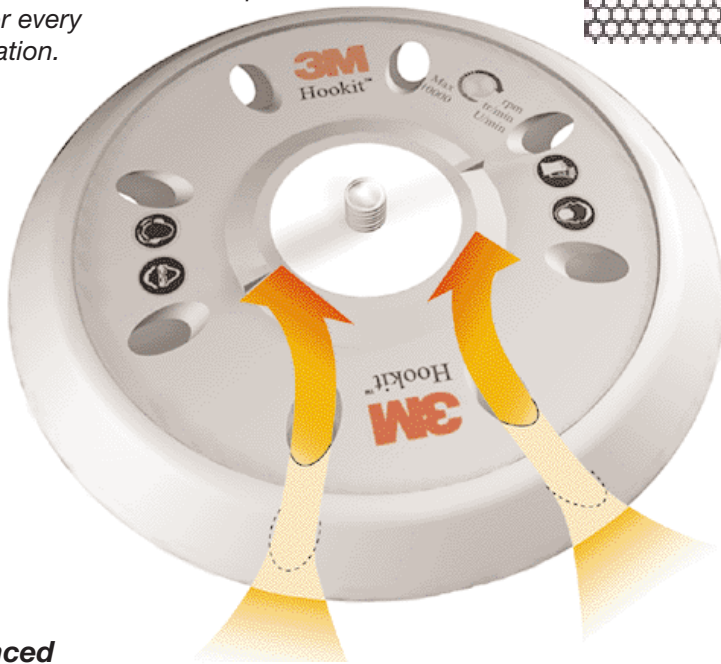

Higher Density Foam

More microcells per cm³ for the same hardness. Creates a more compact pad with longer life and better performance.

New Design

Flat, rigid centre. More softness on the edges.

Fully moulded pads

Tough and durable. 10,000 RPM rated.

'Direct Flow' extraction channelling

Creates optimum dust extraction for cleaner abrasive and longer disc life.

Standard and Soft Pads

Colour coded for easy identification
White/standard for general purpose applications. Black/soft for fine finish applications.

Balanced and weighted Pads

In 5/16" and M8 attachments to suit all sanding machines.



 
5/16"



M8




The Choice Is Yours



600A

6 hole 150mm format for key disc conversions

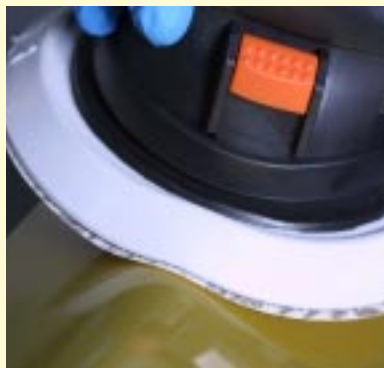

Part No	Stock No	Description
59000	GC800928712	Hookit BUP LD601A holed 5/16-UNF Standard
59001	GC800928704	Hookit BUP LD601A holed 5/16-UNF Soft
59012	GC800930114	Hookit BUP LD601A holed M8 Standard
59013	GC800930122	Hookit BUP LD601A holed M8 Soft



Automotive Aftermarket,
3M United Kingdom PLC,

Tel: 016 1237 6391
Fax: 016 1237 5911
aadenquiries.uk@mmm.com

Automotive Aftermarket,
3M Ireland,

Tel: (01) 280 3555
Fax: (01) 280 3509

EL45

AB596

Printed in UK 1/03