


Technical data

51138

One direction thrust ball bearings

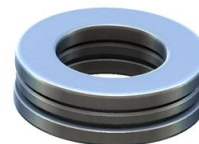

VISUAL (S)



PRODUCT DEFINITION

Brand	NTN
d - Internal diameter	190 mm
D - External diameter	240 mm
T - Thrust bearing height	37 mm
rs - Min fillet radius	1,1 mm
Mass	3,75 kg

PRODUCT PERFORMANCE

Ca - Dynamic axial load rating	170000000 mN
C0a - Static axial load rating	655000000 mN
Cua - Limit axial load rating	20200000 mN
N lim - Oil lubrication limit speed	8400 °/s
N lim - Grease lubrication limit speed	5880 °/s
Tmin - Min operating temperature	233,15 °K
Tmax - Max operating temperature	393,15 °K

ABUTMENT

Da max - Max shoulder diameter OR	210 mm
da min - Min shoulder diameter IR	220 mm

