



SOLARIS DUO



Quick lock /release



Stability feet



Optional orange case



Extendable handle and wheels



Battery status indicator




- High powered LED floodlight system
- Up to 28000 lumens (DUO)
- 360° Swivel and 180° tilting head
- 5 Light modes
- Case; sturdy, stackable, unlimited lifetime guarantee
- 4 Section extendable mast; extends from 500mm-1800mm;
- Quick lock/release system


SOLARIS DUO

The SOLARIS DUO offers a real alternative to generator powered lights, offering a very high light output up to 28,000 lumens.

It is lightweight and all parts are housed in an unbreakable plastic case. It has wheels and pull-up handle for easy transportation. Telescopic poles elevate the lights to 2 metres and have built-in stability legs.

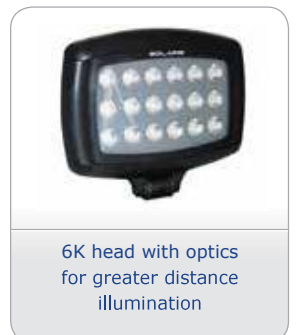

6K head with optics for greater distance illumination

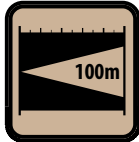

Two optional battery choices	Powered by LI-ION Technology SOLARIS DUO 36Ah 16.4kg	Powered by LI-ION Technology SOLARIS DUO 50Ah 17.3kg
Battery	14.8V 36Ah Li-ion	14.8v 50Ah Li-ion
Charge time	4h	6h
Product weight (kg)	16.4	17.3
Boxed weight (kg)	17.1	18

14K HEAD OPTION - Widespread flood					
Run time - 1 Head	70h	21h	8.5h	3.25h	100h 23.25h 11.75h 4.75h
- 2 Head	35h	10.5	4.25	1.6	50h 11.6 5.9 2.4
Light output	1000	3500	6000	14000	1000 3500 6000 14000
Part No.	NSSOLARIS214K-LI-ION36A			NSSOLARIS214K-LI-ION50A	

6K HEAD OPTION - Built in optics for extra distance				
Run time - 1 Head	14h	6h	20h 8h	
- 2 Head	7h	3h	10h 4h	
Light output	3500	6000	3500 6000	
Part No.	NSSOLARIS26K-LI-ION-36A		NSSOLARIS26K-LI-ION-50A	

SOLARIS DUO LI-ION	
Product size (mm)	L250 x D450 x H540
Boxed size (mm)	L270 x D470 x H560
Head size (mm)	L300 x D58 x H248
Case size (mm)	L570 x D340 x H250

OPTIONAL EXTRAS
Red, green, blue, yellow
35A charger to enable use of lamp whilst charging battery
Car adaptor
Case can be black or yellow