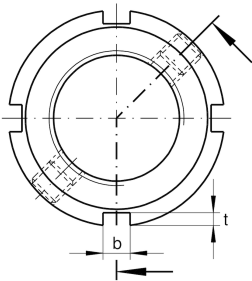
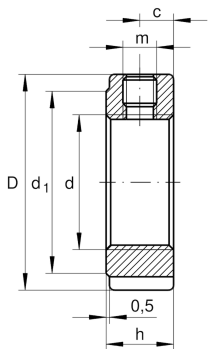
**ZM40** **Precision locknut**

Precision locknut ZM, accessory ZM..

Technical information**Main Dimensions & Performance Data**

d	M40X1,5	Thread
D	58 mm	Outside diameter
h	14 mm	Height
M _A	5 Nm	Mounting torque set screw
F _{aB}	157,000 N	Breaking load, axial
M _L	95 Nm	Breakawag
M _{AL}	55 Nm	Mounting torque reference
M _M	0.945 kg*cm ²	Mass moment of inertia
≈m	142.2 g	Weight

Dimensions

d ₁	52 mm	Plant diameter outside
t	2.5 mm	Hight retaining slot
b	6 mm	Width retaining slot
c	7 mm	Distance bore
m	M6	Threaded - threaded pin