


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **5056070000**
Status: **Active**
Overview: CP Wire-to-Board and Wire-to-Wire Connector Systems
Description: 2.50mm and 3.30mm Pitch Crimp Terminal, Female, 18-22 AWG, Reel

Documents:

Drawing (PDF)	Application Specification AS-504693-001-001 (PDF)
Product Specification 5056050000-000 (PDF)	Application Specification AS-504693-002-001 (PDF)
Product Specification PS-504693-001-001 (PDF)	Packaging Specification 5056079200-200 (PDF)
Application Specification 5056050000-A00 (PDF)	RoHS Certificate of Compliance (PDF)
Application Specification 5056050000-A01 (PDF)	Product Literature (PDF)

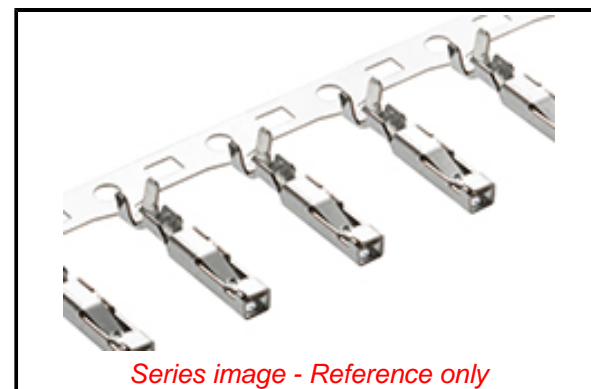

General

Product Family	Crimp Terminals
Series	505607
Application	Signal
Crimp Quality Equipment	Yes
Overview	CP Wire-to-Board and Wire-to-Wire Connector Systems
Packaging Alternative	505607-0100 (Loose)
Product Literature Order No	987651-6581
Product Name	CP-3.3
UPC	889056802390

Physical

Gender	Female
Material - Metal	Copper Alloy
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	113.000/mg
Packaging Type	Reel
Plating min - Mating	0.914µm
Plating min - Termination	0.914µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.55-2.60mm
Wire Size AWG	18, 20, 22
Wire Size mm ²	N/A

Electrical

Current - Maximum per Contact	6.0A
Voltage - Maximum	300V AC (RMS)/DC

Material Info

Reference - Drawing Numbers

Application Specification	5056050000-A00, 5056050000-A01, AS-504693-001-001, AS-504693-002-001
Packaging Specification	5056079200-200
Product Specification	5056050000-000, PS-504693-001-001
Sales Drawing	5056070000-000

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

China RoHS

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[505607 Series](#)

Use With

[504693](#) , [505605](#)