


# C123

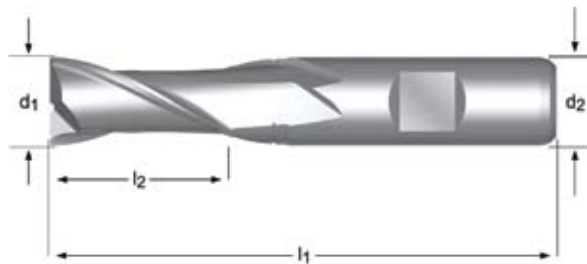

- Slot Drill
- Langlochfräser
- Spiebaanfrezen
- Fraises à rainurer
- Fresas Frontales
- Fresa de Ranhurar



## C123



- 1.1 1.2 4.1 5.1 6.1 6.2 6.3
- 1.3 1.4 2.1 3.1 3.2 3.3 3.4 4.2 5.2 7.1 7.2 7.3 8.1

d <sub>1</sub> Ø mm	d <sub>2</sub> Ø mm	l <sub>2</sub> mm	l <sub>1</sub> mm	z e-Code	d <sub>1</sub> Ø mm	d <sub>2</sub> Ø mm	l <sub>2</sub> mm	l <sub>1</sub> mm	z e-Code
2.00	6	7	51	2 C1232.0	10.00	10	22	72	2 C12310.0
2.50	6	8	52	2 C1232.5	11.00	12	22	79	2 C12311.0
3.00	6	8	52	2 C1233.0	12.00	12	26	83	2 C12312.0
3.50	6	10	54	2 C1233.5	13.00	12	26	83	2 C12313.0
4.00	6	11	55	2 C1234.0	14.00	12	26	83	2 C12314.0
4.50	6	11	55	2 C1234.5	15.00	12	26	83	2 C12315.0
5.00	6	13	57	2 C1235.0	16.00	16	32	92	2 C12316.0
5.50	6	13	57	2 C1235.5	18.00	16	32	92	2 C12318.0
6.00	6	13	57	2 C1236.0	20.00	20	38	104	2 C12320.0
6.50	10	16	66	2 C1236.5	22.00	20	38	104	2 C12322.0
7.00	10	16	66	2 C1237.0	25.00	25	45	121	2 C12325.0
7.50	10	16	66	2 C1237.5	30.00	25	45	121	2 C12330.0
8.00	10	19	69	2 C1238.0	32.00	32	53	133	2 C12332.0
8.50	10	19	69	2 C1238.5	36.00	32	53	133	2 C12336.0
9.00	10	19	69	2 C1239.0	40.00	40	63	155	2 C12340.0
9.50	10	19	69	2 C1239.5					