



Brand of NTN corporation


Technical data

BBES12UU

Standard ball bushings closed



VISUAL (S)

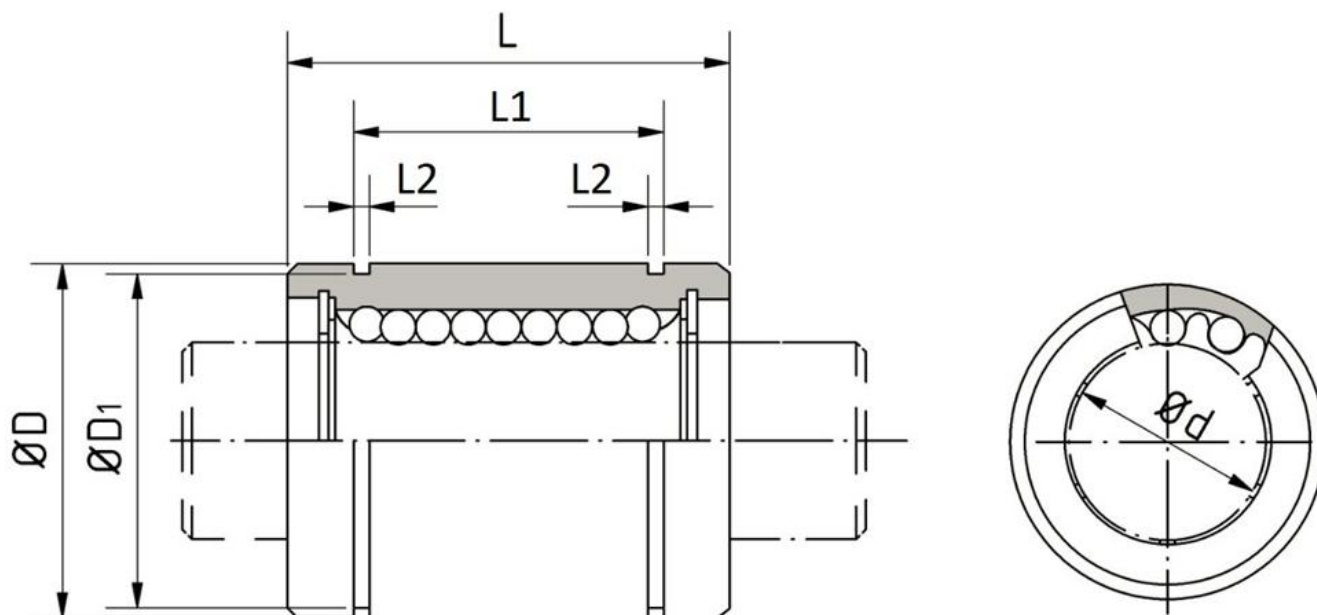

PRODUCT DEFINITION

Brand	SNR
Design type	BBE
Ball bushings category	Standard ball bushings, closed
Standard	ISO dimension
Number of seals	2
Material outer cylinder or steel segments	X105CrMo17
Material Cage	PA
Initial greasing	Non/No
d - Internal diameter	12 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION	
d - Internal diameter tolerance	0.008/0
D - External diameter	22 mm
D - External diameter tolerance	0/-0,009
L - Length	32 mm
L - Length tolerance	0/-0,2
L1	22,9 mm
L1 tolerance	0/-0,2
D1 - Diameter	21 mm
L2	1,3 mm
Number of ball rows	4
Mass	0,045 kg

PRODUCT PERFORMANCE	
Cmin	0,416 kN
Cmax	0,588 kN
C0min	0,784 kN
C0max	1,109 kN
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	80 °C

ESHOPDONOTDISPLAY	
Reference	BBS12UU
Image	BBE+BB_1.JPG, BBE+BB_3.JPG
Send to Eshop	Yes
Send to Paper Catalog	Yes



ESHOPDONOTDISPLAY

Tracepart

Oui/Yes

