




BSP Minimesse™ Pressure Test Kit

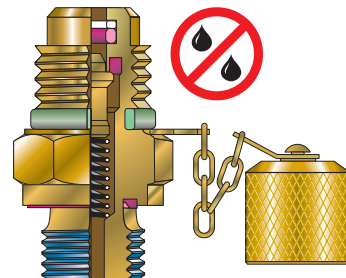

Model: 3101-16-XX.50

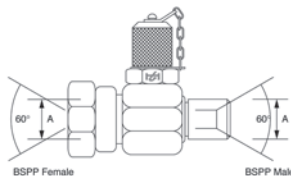

life-time leak free guarantee

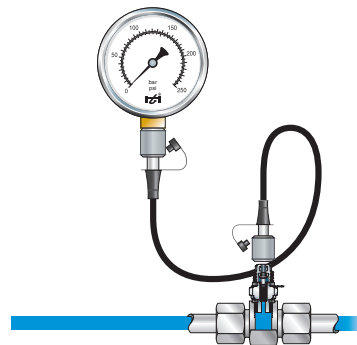

FEATURES:

- Test under pressure using Hydrotechnik leak free minimesse connections up to 630 bar.
- Connect & disconnect under full system pressure. Lifetime leak free guarantee.
- In-line test point tees offer excellent system access versatility.
- Still our most popular & best value kit.
- Printed logo & contact details on kit box.*

KIT CONTENTS

- 2 x 63mm glycerine filled pressure gauges user selectable up to 700 bar.
- 3 x Minimesse™ Male/Swivel Female 1620 inline test point adaptors. 1/4", 3/8" & 1/2" BSP.
- 1 x Minimesse™ 1620 test point - 1/4" BSP. 1 x G1/4" BSP to 1620 gauge adaptor.
- 1 x 630 bar rated Minimesse™ pressure test hose - 1.5 meters long.
- Additional 3/8" & 1/2" BSP male threaded adaptors & seals.

Order code:

3101-16- **X** **X** .50

Replace **X** in above code with pressure gauges required from the following options:

0 = 0 to 7 bar	5 = 0 to 100 bar
1 = 0 to 14 bar	6 = 0 to 170 bar
2 = 0 to 28 bar	7 = 0 to 280 bar
3 = 0 to 40 bar	8 = 0 to 400 bar
4 = 0 to 70 bar	9 = 0 to 700 bar

All pressure gauges have dual bar / psi scale. ±1.6% acc.
 Special gauge ranges available on request

* Minimum orders of 5 kits.