

# DPCB PUNCHED PLAIN COPPER BUSBAR, DOUBLE



## CERTIFICATIONS



## FEATURES

- Heavy-duty power connection
- Circuit breaker, generator and prefabricated power network conductor
- Alternative to large and multiple cables
- Earth/ground connection
- Power distribution
- Rounded edges

## SPECIFICATIONS

**Material:** Copper


Table 1/2						
Catalog Number	Article Number	Width (W)	Thickness (T)	Length (L)	Hole Size (HS)	A
DPCB100X5	550440	3.94"	0.2"	68.9"	0.41"	2.95"
DPCB125X5	550450	4.92"	0.2"	68.9"	0.41"	3.94"
DPCB50X5	550410	1.97"	0.2"	68.9"	0.41"	0.98"
DPCB63X5	550420	2.48"	0.2"	68.9"	0.41"	1 1/2"

Catalog Number	Article Number	Width (W)	Thickness(T)	Length (L)	Hole Size (HS)	A
DPCB80X5	550430	3.15"	0.2"	68.9"	0.41"	2.17"
DPCB100X10	550380	3.94"	0.39"	68.9"	0.41"	2.95"
DPCB120X10	550390	4.72"	0.39"	68.9"	0.41"	3.74"
DPCB50X10	550350	1.97"	0.39"	68.9"	0.41"	0.98"
DPCB60X10	550360	2.36"	0.39"	68.9"	0.41"	1.38"
DPCB80X10	550370	3.15"	0.39"	68.9"	0.41"	2.17"

Table 2/2

Catalog Number	Article Number	B	C	Unit Weight
DPCB100X5	550440	0.98"	0.49"	15.98 lb
DPCB125X5	550450	0.98"	0.49"	20.28 lb
DPCB50X5	550410	0.98"	0.49"	7.5 lb
DPCB63X5	550420	0.98"	0.49"	9.7 lb
DPCB80X5	550430	0.98"	0.49"	12.57 lb
DPCB100X10	550380	0.98"	0.49"	31.97 lb
DPCB120X10	550390	0.98"	0.49"	40.57 lb
DPCB50X10	550350	0.98"	0.49"	15 lb
DPCB60X10	550360	0.98"	0.49"	19.4 lb
DPCB80X10	550370	0.98"	0.49"	25.13 lb

## DIAGRAMS

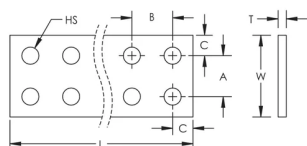

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**