


Digital Optical Audio cable, Braided, Aluminium

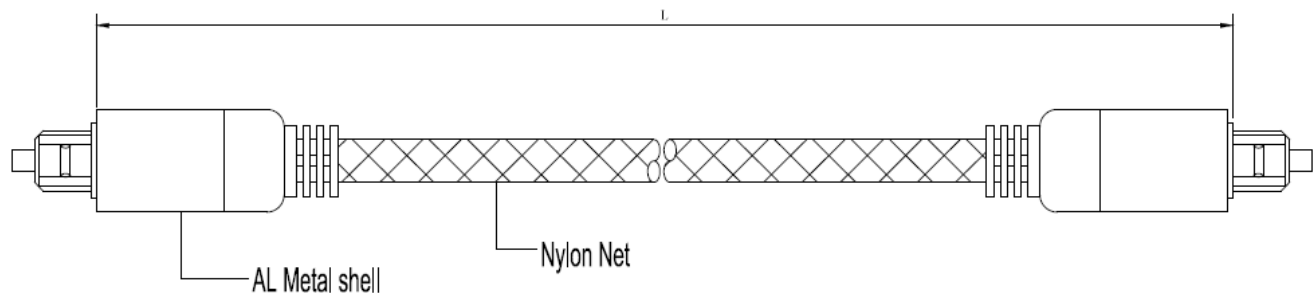

FIBER SPECIFICATION

ITEM		SPEC
CENTER CORE	MATERIAL	PLASTIC FIBER
	CONSTRUCT MM/NO.	0.98MM*1
	O. D. MM	0.98
OUTER COATING	MATERIAL	PE
	O. D. MM	2.2
	COLOR	BLACK
OUTTER SHEATH	MATERIAL	PVC
	O. D. MM	4.0+0.1
	COLOR	ARGENT GREY

TECHNOLOGICAL PARAMETER

ITEM		SPEC
Fiber Diameter		1mm
Outside Diameter		2.2mm
Fiber Material		PMMA
Application Lighwave		650nm
Attenuation		≤ 0.18dB/m
Bend Radius		5Xcore Diameter
Used Temperature		-15。 - 80。
Connection Loss		≤ 0.5dB
Outtter PVC Diameter		4.0+0.1

L												CPAL006				DESCRIPTION		SCALE	1:1	UNITS:MM	3RD ANGLE
																MODEL NO.	OF007-A	△			
																DRAWING NO.		△			
																FINISHING		△	2014/10/31		A1
																MATERIAL		SYM	DATE		REVISION

Cable Power Ltd, 6 Brook House, Wivenhoe Business Centre,
Wivenhoe, Essex, CO7 9DP

www.cablepower.co.uk +44 (0) 1206 825381