


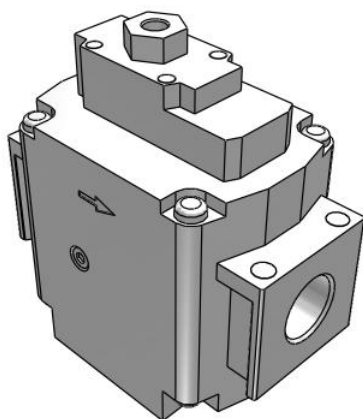

Soft Start Valve, Air Operated Type - AVA-A AVA5000-F06-A

Datasheet


General series information

- Flow rate up to 11908 l/min (ANR)
- Optional built-in silencer
- Operating pressure range: 0.2 to 1.0 MPa
- IP65 enclosure.

Standard specifications

Body Size	5000
Thread	F (G)
Port Size	06 (3/4)
Option	None
Flow Direction/Pressure Unit	Flow direction: left to right
Pressure medium	Air
Maximum temperature of pressure medium	50 °C
Minimum temperature of pressure medium	0 °C
Maximum ambient temperature	50 °C
Minimum ambient temperature	0 °C
Approvals	CE
Protection class with connector	Dust-protected (DIN terminal: IP65)
Weight	1.314 Kg

Dimensions

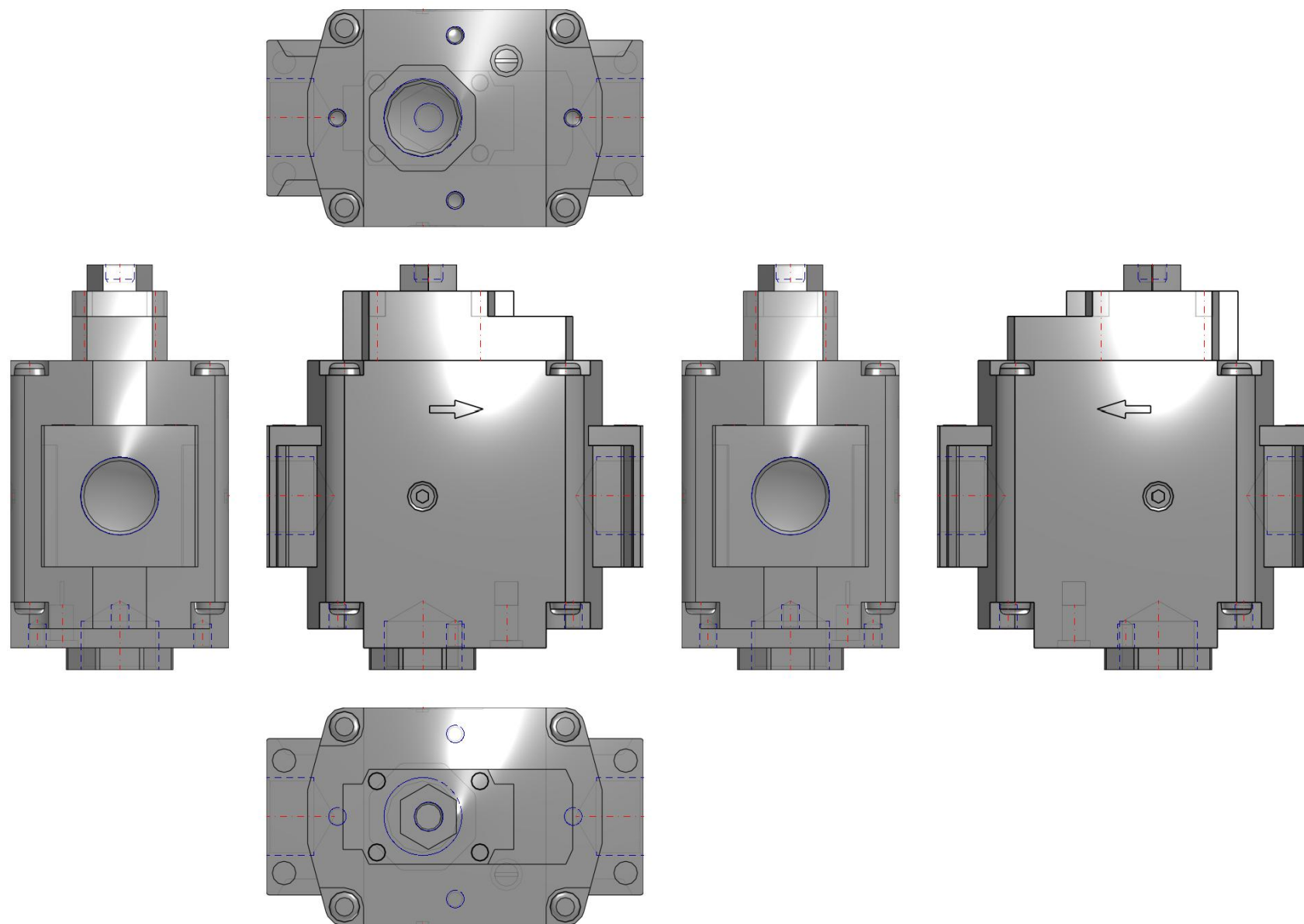

Additional information

Catalogue	AV2-3-4-5000-A-B_EU.pdf
Declaration of conformity	newDoC_AVL_TF1Z007EN.pdf newDoC_AV-A_TF1V02EN.pdf newDoC_AVL_TF122115EN.pdf newDoC_AV-A_TF122111EN.pdf
Installation manuals	IM_AVL-A_TF2Z462EN-C.pdf
Operation manuals	OM_AVx-A_OMZ0091EN-F.pdf