
5626

Lamps with metal bases for trucks



Areas of application

- Position and parking light
- Indicator, brake, fog and reversing lights
- Number plate and side position lights

Product benefits

- OEM Quality
- Wide product range
- Reliable quality

Product features

- Original spare parts

Technical data


Electrical data

Power input	7 W
Nominal wattage	5.00 W
Nominal voltage	24 V
Power input tolerance	±10 %
Test voltage	28.0 V

Photometrical data

Luminous flux	50 lm
Luminous flux tolerance	±25 %

Dimensions & weight

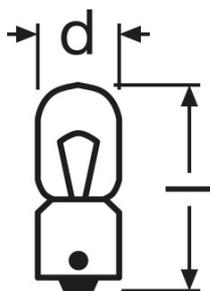

Length	37.5 mm
Diameter	16.0 mm
Product weight	7.00 g

Lifespan

Lifespan B3	80 h
Lifespan Tc	250 h

Additional product data

Base (standard designation)	BA15d
-----------------------------	-------

Certificates & standards

ECE category	R5W
--------------	-----

Country specific categorizations

Product datasheet

Order reference	5626 5W 24V BA1
------------------------	-----------------

Country specific information

Product code	METEL code	SEG-No.	STK-Number	UK Org
4008321095336	OSRA5626	-	-	-

Product datasheet

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4008321095336	5626	Unpacked 1	15 mm x 15 mm x 25 mm	0.01 dm ³	9.00 g
4008321095343	5626	Folding carton box 10	139 mm x 53 mm x 36 mm	0.27 dm ³	83.00 g
4008321095350	5626	Shipping carton box 50	144 mm x 64 mm x 205 mm	1.89 dm ³	465.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.