

**PBS25-XL**

Plummer block housing unit

Plummer block housing units PBS, sheet steel housing, radial insert ball bearing with eccentric locking collar, P seals

X-life

Technical information

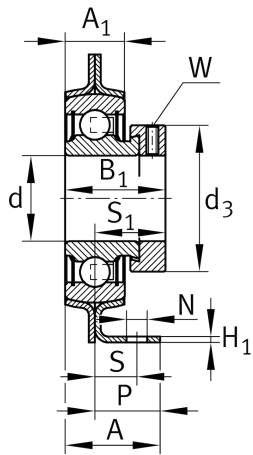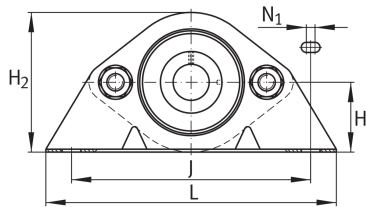

Your current product variant

Material	Steel sheet
----------	-------------

Main Dimensions & Performance Data

d	25 mm	Bore diameter
H ₂	72 mm	Height
L	133.5 mm	Length total
C _{0r} G	3,600 N	Load carrying capacity (housing)
m	0.48 kg	Weight

Mounting dimensions

J	95.5 mm	Distance fixing bore
N	10.5 mm	Width (slot)
N ₁	9.5 mm	Distance slot center
S	14.3 mm	Distance fixing

Dimensions

H	36.5 mm	Distance shaft axis
A	34.1 mm	Width (base)
A ₁	17.4 mm	Width (head)
H ₁	3.4 mm	Height (base)
P	25.4 mm	Distance support



Additional information

GEH52-PBS	Housing
RAE25-XL-NPP-B	Bearing designation

Temperature range

T _{min}	-20 °C	Operating temperature min.
T _{max}	120 °C	Operating temperature max.