

Features

- Available in different sizes


RS PRO LED LAMP

RS Stock No.: 0687565

0687651

0687675

0687804

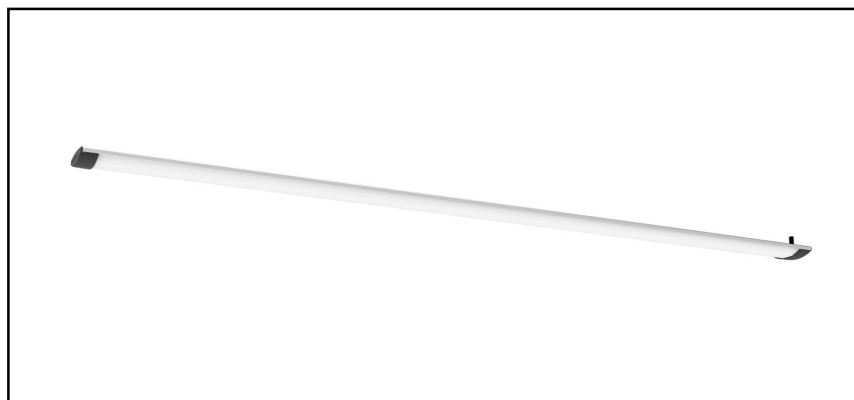

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

Lighting is crucial in any workspace, and our LED lamp provides even and precise illumination that enhances both comfort and work efficiency. The LED lamps are available in three lengths: 60 cm, 120 cm, and 180 cm, to perfectly match various widths of workbenches.

For workbenches with a width of 1200 mm, we recommend the 600 mm lamp; for benches with a width of 1500 mm the 1200 mm lamp; for benches with a width of 1800 mm, the 1800 mm lamp; and for benches with a width of 2000 mm, the 1800 mm lamp. This tailored approach ensures optimal lighting that eliminates shadows and allows for precise task execution.

The LED lamp, with power ranging from 20 W to 60 W, offers excellent energy efficiency, resulting in lower energy consumption and a longer lifespan. Powered by 230 V, it provides stable and reliable performance. Its IP 65 protection rating guarantees resistance to dust and water, making it an ideal solution for environments where conditions may be challenging. Additionally, the IK 08 mechanical resistance ensures durability against impacts and mechanical damage.

With a light distribution angle of 120°, the LED lamp provides wide and even illumination, minimizing eye strain and improving work comfort. Thanks to precisely selected lighting parameters, our lamps perform exceptionally well in various applications, from workshops to offices, where high-quality lighting is essential.

By choosing our LED lamp, you ensure that your workspace will be adequately lit, which will enhance both efficiency and comfort.

Accessories compatible with L & H Type workbenches

Accessory Type: LED LAMP

Stock No.	Product Name	Compatible RS PRO ESD workbench (mm)
0687565	LED lamp 600mm	1200
0687651	LED lamp 1160mm	1500
0687675	LED lamp 1725mm	1800
0687804	LED lamp 1725mm	2000