


Product Name // M8 Series A Code TPU Right-Angle
Overmould Flex Cable Connector 3 Contact Pins Pre-Wired
With 1M PUR Jacket Cable

 [View Product Page](#)

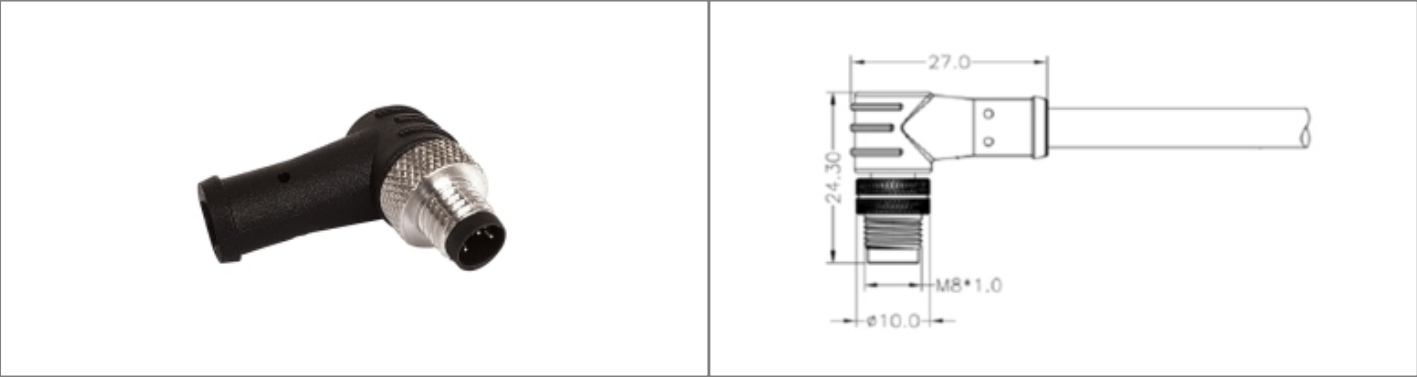

// Product Description:	
M8 Series Right-Angle Overmould Flex Body Connectors	3, 4, 5 Contact (3, 4 Contact are A Code, 5 Contact are B Code)
Water and dustproof to IP67 when mated with compatible connector	Overmould cable Termination with choice of lead lengths and choice of PVC or PUR jacket cable, depending on part code
Pin or Socket	Mate with M8 Series Flex Body, Inline Body and Panel Mount Connectors, depending on part code

// General Information:	
Product Display Title:	M8 Series Right-Angle Overmould Flex Body Connectors
Product Family:	Circular Automation Connectors
Product Series:	M8 Series
Approvals:	CSA, ENEC, UL, VDE, RCM
Body Material:	TPU
Cable Length:	1m
Contact Type:	Plug Contact
Coupling Type:	Screw
Current Max:	3A
Diameter Over Coupling Ring Mm:	12.5mm
Function:	Right Angle Flex Connector Single Ended Cable
Ip Rating:	IP67
Max Operating Temperature:	+80°C
Min Operating Temperature:	-25°C
Number Of Contacts:	3 Contacts
Pin Layout Code:	A Code
Sheath Material:	PUR
Thread Size:	M8 x 1
Voltage Max:	60V

// Product PDF Links

 M8 Series automation connectors...

// Product 3D CAD Model Links

 PXPTPU08RAM03ACL010PUR3D CAD Mod