

## Datasheet

### **RS Pro E10 Filament Indicator Lamp, Clear, 2.8 V, 850 mA, 10h**

RS Stock No: **655-9277**



## Product Details

RS Pro E10 filament indicator lamp comes with clear lens. It has a voltage rating of 2.8 V and current rating of 850 mA. The lamp has 10 h life. The MES tungsten halogen filament lamp is suitable for use with many popular torches and hand lamps.

## Features and Benefits

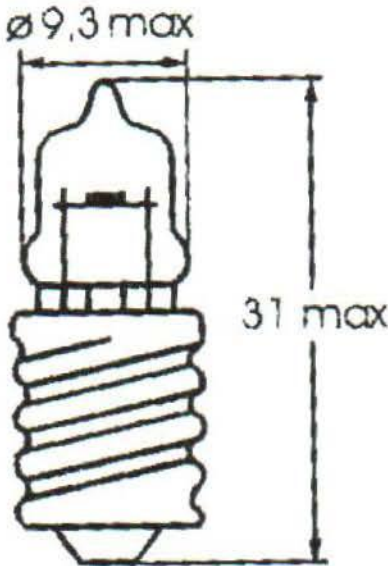
- Voltage rating of 2.8 V
- Current rating of 850 mA
- 10 hours lifetime



ENGLISH

### Specifications:

Current Rating	850 mA
Diameter	9.3 mm
Lamp Base	E10
Lamp Size	T9
Length	31 mm
Lens Colour	Clear
Life Hours	10 h
Luminosity	35 lm
Voltage Rating	2.8 V

RS Stock No. 6559277		
<p><i>DRAWING - I</i></p>  <p>Unit : mm</p>		
1. Structure	Bulb Type	T9X30
	Bulb Diameter	Ø 9.3Max.
	Length	31.0Max
	Base Type	E10
2. Design Characteristics	Voltage	2.8V
	Amperage	850mA±10%
	Filament Type	Vacuum type
	Luminous Flux	35Lm±20%
	Life Hours	10Hrs